


Technical datasheet: KP3040SP1-5838

Specifications:

Input power	Rated 0.8W / Max. 1.5W
Impedance	$8\Omega \pm 15\% \Omega$ (1Vrms at 1.5KHz)
Frequency Range	0Hz to 7kHz
Resonant Frequency	650Hz \pm 20%Hz
Distortion	<10% Max. at 1kHz/0.8W
Out-diameter	$\varnothing 30\text{mm}$
Height	4mm
Weight	6g
SPL	90dB \pm 3dB (0.1W/0.1M at 1kHz)
Buzz and Rattle	No audible buzzes, rattles when 2.53V sine wave signal is swept at frequency range.

Dimensions:

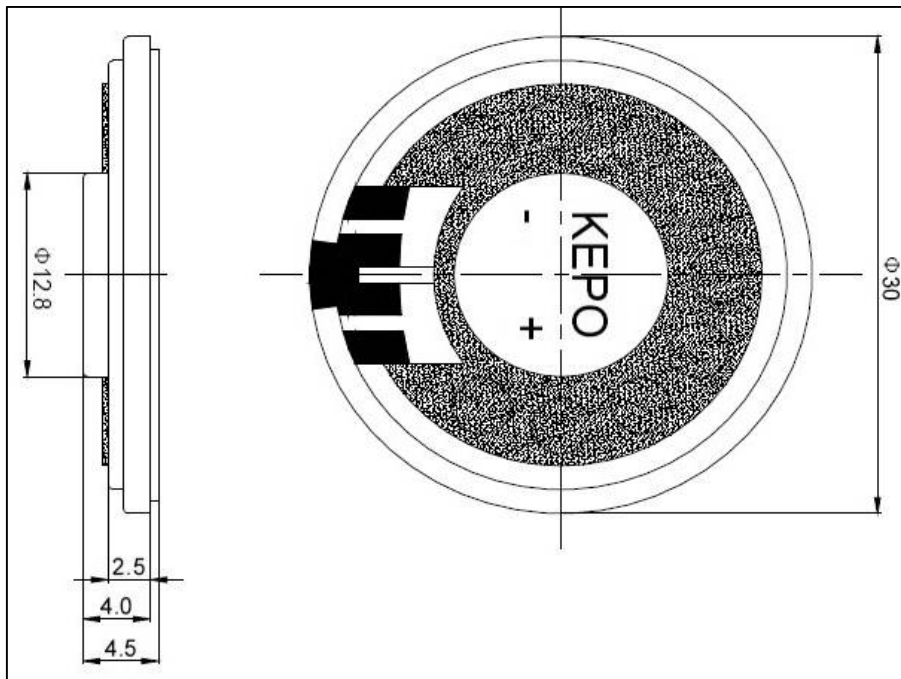

Frequency Response:

