



APC Back-UPS 650VA, 120V, 8 NEMA outlets (4 surge)

Brand : APC

Product code: BE650G1


Product name : Back-UPS 650VA, 120V, 8 NEMA outlets (4 surge)



Back-UPS 650VA, 120V, 8 NEMA outlets (4 surge)

APC Back-UPS 650VA, 120V, 8 NEMA outlets (4 surge). Output power capacity: 0.65 kVA, Output power: 390 W, Input operation voltage (min): 90 V. AC outlet types: NEMA 5-15R, AC outlets quantity: 8 AC outlet(s). Battery technology: Sealed Lead Acid (VRLA), Battery recharge time: 24 h. Form factor: Compact, Product colour: Black, Cable length: 1.52 m. Compliance certificates: RoHS, Certification: UL 1449, CSA C22.2 No. 107.1,FCC Part 15 Class B,FCC Part 68,NOM,TUV-C,UL 1778

Features		Design	
Output power capacity *	0.65 kVA	Cable length	1.52 m
Output power *	390 W	Product colour *	Black
Input operation voltage (min) *	90 V	LED indicators	✓
Input operation voltage (max) *	140 V	Operational conditions	
Input frequency *	50/60 Hz	Operating temperature (T-T)	0 - 40 °C
Output operation voltage (min)	120 V	Storage temperature (T-T)	-15 - 45 °C
Output operation voltage (max)	120 V	Operating relative humidity (H-H)	5 - 95%
Maximum current	12 A	Storage relative humidity (H-H)	5 - 95%
Surge energy rating	340 J	Operating altitude	0 - 3000 m
Noise level	45 dB	Non-operating altitude	0 - 15000 m
Audible alarm(s)	✓	Certificates	
Audible alarm modes	Battery replacement	Compliance certificates	RoHS
Ports & interfaces		Certification	UL 1449, CSA C22.2 No. 107.1,FCC Part 15 Class B,FCC Part 68,NOM,TUV-C,UL 1778
AC outlet types	NEMA 5-15R	Weight & dimensions	
AC outlets quantity	8 AC outlet(s)	Width	180 mm
USB 2.0 ports quantity	1	Depth	284 mm
Ethernet LAN (RJ-45) ports	1	Height	86 mm
Battery		Weight	6.2 kg
Battery technology	Sealed Lead Acid (VRLA)	Packaging data	
Battery recharge time	24 h	Package weight	7 kg
Hot-swap battery	✓	Other features	
Automatic battery test	✓	Interface	USB
Cold start	✓	Output connections	8 x NEMA 5-15R
Design		Input connection type	NEMA 5-15P
Form factor *	Compact	Networking features	10/100Base T
		Package dimensions (WxDxH)	226 x 386 x 127 mm

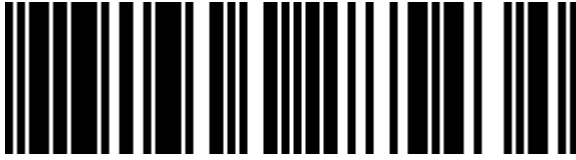

0731304285434



731304285434

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.