

StarTech.com 16 Port 1U Rackmount USB KVM Switch with OSD

Brand : StarTech.com

Product code: SV1631DUSB

Product name : 16 Port 1U Rackmount USB KVM Switch with OSD



16 Port 1U Rackmount USB KVM Switch with OSD

StarTech.com 16 Port 1U Rackmount USB KVM Switch with OSD. Keyboard port type: USB, Mouse port type: USB, Video port type: VGA. Maximum resolution: 1920 x 1440 pixels. Product colour: Black, Rack capacity: 1U, Housing material: Steel. Input voltage: 110-240 V, Input current: 0.8 A, Output voltage: 12 V. Width: 540 mm, Depth: 180 mm, Height: 45 mm



Ports & interfaces

Number of computers controlled *	16
Keyboard port type *	USB
Mouse port type *	USB
Video port type *	VGA
Console ports *	USB A, VGA (D-Sub)
Console USB ports quantity	2
Audio connections	✗
DC-in jack	✓

Performance

Maximum resolution *	1920 x 1440 pixels
Plug and Play	✓
Daisy chain	✓

Design

Rack mounting *	✓
Rack capacity	1U
Product colour *	Black
Housing material	Steel
LED indicators	✓

Display

Built-in display *	✗
--------------------	---

Power

Input voltage	110-240 V
Input current	0.8 A
Output voltage	12 V

Power

Output current	1.5 A
Power plug type	Type M

Operational conditions

Operating temperature (T-T)	5 - 40 °C
Storage temperature (T-T)	-20 - 60 °C
Operating relative humidity (H-H)	5 - 80%

Weight & dimensions

Width	540 mm
Depth	180 mm
Height	45 mm
Weight	3.1 kg

Packaging data

Package width	89 mm
Package depth	468 mm
Package height	264 mm
Package weight	3.53 kg

Packaging content

Manual	✓
AC adapter included	✓

Other features

Audio support	✗
IP control	✗

Logistics data


Harmonized System (HS) code	85176200
-----------------------------	----------



0065030837224



065030837224

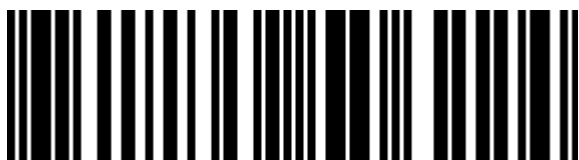

0741199506224



741199506224

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.