



Lenovo 4XC7A08242 network card Internal Fiber 25000 Mbit/s

Brand : Lenovo


Product code: 4XC7A08242

Product name : 4XC7A08242



ThinkSystem Broadcom 57454 10/25GbE SFP28 4-port OCP Ethernet Adapter
Lenovo 4XC7A08242. Internal. Connectivity technology: Wired, Host interface: PCI Express, Interface: Fiber. Maximum data transfer rate: 25000 Mbit/s. Product colour: Green, Stainless steel

Ports & interfaces		Design	
Connectivity technology *	Wired	Component for *	Server
Host interface *	PCI Express	Product colour	Green, Stainless steel
Interface *	Fiber	Internal *	✓
Fiber ports quantity	4	Certification	CB, cTUVus, CE, FCC, VCCI, ICES, RCM
Fiber optic connector	SFP28	Compatible products	SR655/SR635
PCI version	3.0		
Network		Operational conditions	
Maximum data transfer rate *	25000 Mbit/s	Operating temperature (T-T)	0 - 55 °C
	IEEE 802.1Q, IEEE 802.1Qau, IEEE 802.1Qaz, IEEE 802.1Qbb, IEEE 802.1Qbg, IEEE 802.3ad, IEEE 802.3az	Storage temperature (T-T)	-40 - 65 °C
Networking standards *		Operating relative humidity (H-H)	5 - 95%
		Storage relative humidity (H-H)	5 - 95%
Ethernet LAN	✓	Logistics data	
Ethernet interface type	25 Gigabit Ethernet	Harmonized System (HS) code	85176990
Ethernet LAN data rates	25000 Mbit/s		

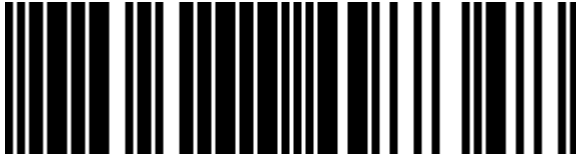

0889488497348



889488497348

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.