

Viewsonic PF0730-I0WW graphic tablet Wood 5080 lpi 162.6 x 101.6 mm USB

Brand : Viewsonic

Product code: PF0730-I0WW

Product name : PF0730-I0WW


- Natural Writing Experience for Distance Learning
- Works with Any Paper Type without Restriction
- Pure Performance from a Real Pen
- Compatible with Education and Design Software
- Compatible with Windows 7 or later, Mac OS 10.15 or later

PF0730-I0WW ViewBoard Notepad, 5080 LPI, 250 PPS, 4096 Levels, Windows 7 and above, MAC OS X10.15 or higher

Viewsonic PF0730-I0WW. Connectivity technology: Wired, Resolution: 5080 lpi, Working area: 162.6 x 101.6 mm. Accuracy pen: 0.25 mm. Product colour: Wood. Width: 200 mm, Depth: 7.5 mm, Height: 170 mm. Package width: 465 mm, Package depth: 300 mm, Package height: 515 mm



Tablet		Weight & dimensions	
Resolution *	5080 lpi	Depth	7.5 mm
Working area *	162.6 x 101.6 mm	Height	170 mm
Device interface *	USB	Packaging data	
Tablet input type	Pen	Package width	465 mm
Connectivity technology *	Wired	Package depth	300 mm
Pen		Package height	515 mm
Pen included *	✓	Package weight	543.5 g
Accuracy pen	0.25 mm	Packaging content	
Features		Cables included	USB
Product colour *	Wood	Pen holder	✓
Windows operating systems supported	✓	Number of pen tips	1
Mac operating systems supported	✓	Number of pen nibs	1
Weight & dimensions		Logistics data	
Width	200 mm	Products per master (outer) case	20 pc(s)
		Harmonized System (HS) code	8471607000

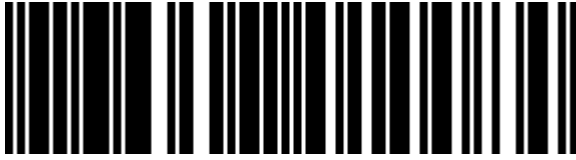

0766907010084



766907010084

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.