



Lenovo 4X67A13135 graphics card NVIDIA A100 40 GB High Bandwidth Memory 2 (HBM2)

Brand : Lenovo
Product code: 4X67A13135
Product name : 4X67A13135




ThinkSystem NVIDIA A100 40GB PCIe Gen4 Passive GPU

Lenovo 4X67A13135 graphics card NVIDIA A100 40 GB High Bandwidth Memory 2 (HBM2):

The NVIDIA A100 Tensor Core GPU delivers acceleration at every scale for AI, data analytics, and HPC to tackle the world’s toughest computing challenges. As the engine of the NVIDIA data center platform, A100 can efficiently scale up to thousands of GPUs or, using new Multi-Instance GPU (MIG) technology, can be partitioned into seven isolated GPU instances to accelerate workloads of all sizes. A100’s third-generation Tensor Core technology now accelerates more levels of precision for diverse workloads, speeding time to insight as well as time to market.

Lenovo 4X67A13135. Graphics processor family: NVIDIA, Graphics processor: A100. Discrete graphics card memory: 40 GB, Graphics card memory type: High Bandwidth Memory 2 (HBM2). Interface type: PCI Express 4.0. Cooling type: Passive

Processor		Memory	
CUDA *	✓	Memory bandwidth (max)	32 GB/s
CUDA cores	6912	Ports & interfaces	
Graphics processor family *	NVIDIA	Interface type *	PCI Express 4.0
Graphics processor *	A100	Design	
Memory		Cooling type *	Passive
Discrete graphics card memory *	40 GB	Form factor	Full-Height/Full-Length (FH/FL)
Graphics card memory type *	High Bandwidth Memory 2 (HBM2)	Product colour	Black, Gold
Data transfer rate	1.555 Gbit/s	Power	
		Power consumption (typical) *	250 W

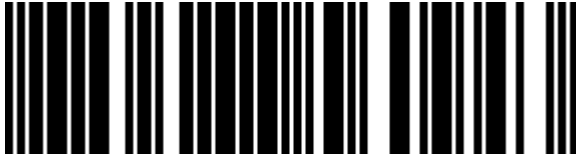

0889488560943



889488560943

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.