



Lenovo 4XC7A80269 network card Internal Ethernet 25000 Mbit/s

Brand : Lenovo
Product code: 4XC7A80269
Product name : 4XC7A80269




ThinkSystem Intel E810-DA4 10/25GbE SFP28 4-Port OCP Ethernet Adapter

Lenovo 4XC7A80269 network card Internal Ethernet 25000 Mbit/s:

The ThinkSystem Intel E810-DA4 10/25GbE SFP28 network adapter improve application efficiency and network performance with innovative and versatile capabilities. With four 25GbE SFP28 ports and key performance optimizations, the E810 adapter supports solutions across Cloud, Enterprise, and Communications.
Lenovo 4XC7A80269. Internal. Connectivity technology: Wired, Host interface: PCI Express, Interface: Ethernet. Maximum data transfer rate: 25000 Mbit/s

Ports & interfaces		Design	
Connectivity technology *	Wired	Internal *	✓
Host interface *	PCI Express	Form factor	OCP 3.0
Interface *	Ethernet	Certification	FCC B UL CE VCCI BSMI RCM KCC
PCI version	4.0	Operational conditions	
Network		Operating temperature (T-T)	0 - 55 °C
Maximum data transfer rate *	25000 Mbit/s	Storage temperature (T-T)	-40 - 70 °C
Networking standards *	IEEE 1588v2	Operating relative humidity (H-H)	10 - 90%
Ethernet interface type	10 Gigabit Ethernet, 25 Gigabit Ethernet	Weight & dimensions	
Design		Width	76 mm
Component for *	Server	Depth	115 mm

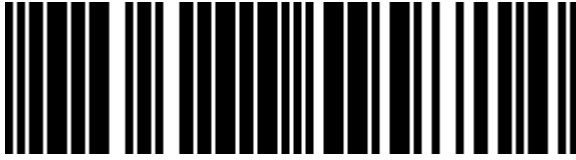

0889488599714



889488599714

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.