



APC Easy Rack, 24U, Black, With Roof, Castors, Feet, 4 Brackets, and Side Panels, No Bottom, 1198H x 600W x 1200D mm

Brand : APC

Product code: ER6422

Product name : Easy Rack, 24U, Black, With Roof, Castors, Feet, 4 Brackets, and Side Panels, No Bottom, 1198H x 600W x 1200D mm

Easy Rack, 24U, Black, With Roof, Castors, Feet, 4 Brackets, and Side Panels, No Bottom, 1198H x 600W x 1200D mm


APC Easy Rack, 24U, Black, With Roof, Castors, Feet, 4 Brackets, and Side Panels, No Bottom, 1198H x 600W x 1200D mm. Type: Freestanding rack, Rack capacity: 24U, Maximum weight capacity: 1199.75 kg, Key lock, Adjustable feet, Castor wheels, Product colour: Black



Explore APC EASY Rack series with augmented reality (AR) in 3D!



Features		Features	
Rack capacity *	24U	Certification	UL 2416 UL 60950-1 EIA-310E
Type *	Freestanding rack	Weight & dimensions	
Maximum weight capacity *	1199.75 kg	Size (imperial)	48.3 cm (19")
Maximum weight capacity (rolling)	599.65 kg	Width	600 mm
Product colour	Black	Depth	1200 mm
Product design	4-post	Height	1198 mm
Back door construction	Mesh	Mounting depth (max)	104.1 cm
Side panels included	✓	Packaging data	
Key lock	✓	Package width	1250 mm
Back door key lock	✓	Package depth	650 mm
Front door key lock	✓	Package height	1330 mm
Side panel key lock	✓	Package weight	82 kg
Adjustable feet	✓	Technical details	
Castor wheels	✓	Total carbon footprint (kg of CO2e)	248.81
Preassembled	✓	Logistics data	
		Harmonized System (HS) code	85381000

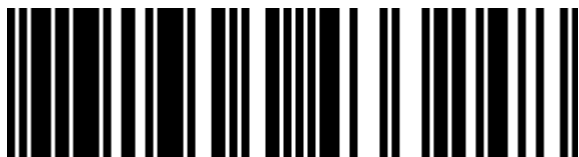

0731304433248



731304433248

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.