



Lenovo 4Y37A72480 interface cards/adapter Internal SAS

Brand : Lenovo

Product code: 4Y37A72480

Product name : 4Y37A72480



ThinkSystem 4350-8i SAS/SATA 12Gb HBA


Lenovo 4Y37A72480 interface cards/adapter Internal SAS:

The Lenovo ThinkSystem 4350-8i and 4350-16i SAS/SATA 12Gb HBAs are high performance host bus adapters for internal storage connectivity in ThinkSystem servers. They integrate the latest SAS technology and offer eight or 16 lanes of 12 Gbps SAS.

This product guide provides essential presales information to understand the ThinkSystem internal HBAs and their key features, specifications, and compatibility. This guide is intended for technical specialists, sales specialists, sales engineers, IT architects, and other IT professionals who want to learn more about the HBAs and consider their use in IT solutions.

Lenovo 4Y37A72480. Host interface: PCIe, Output interface: SAS, Host interface gender: Female. Product colour: Multicolour, Purpose: Server, Certification: FCC Part 15 Class A Australia/New Zealand (AS/NZS 3548) Canada (ICES-003 Class B) Europe (EN55032/EN55024) Japan VCCI Korea KCC RoHS compliant EN/IEC/UL 60950 USA (FCC 47 CFR part 15 Subpart B class B) Data transfer rate (max): 12 Gbit/s. Width: 167 mm, Height: 64 mm

Ports & interfaces		Design	
Host interface *	PCIe	Certification	FCC Part 15 Class A Australia/New Zealand (AS/NZS 3548) Canada (ICES-003 Class B) Europe (EN55032/EN55024) Japan VCCI Korea KCC RoHS compliant EN/IEC/UL 60950 USA (FCC 47 CFR part 15 Subpart B class B)
Host interface gender	Female		
Output interface *	SAS		
Expansion card form factor	Low-profile		
Expansion card standard	PCI 3.0		
Internal mini-SAS ports	2		
Design		Features	
Internal *	✓	Data transfer rate (max)	12 Gbit/s
Product colour	Multicolour	Operational conditions	
Purpose	Server	Operating temperature (T-T)	0 - 55 °C
		Operating relative humidity (H-H)	10 - 90%
		Weight & dimensions	
		Width	167 mm
		Height	64 mm

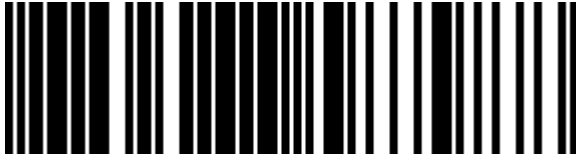

0889488587988



889488587988

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.