



AOC AS110DX monitor mount / stand 81.3 cm (32") Desk Black

Brand : AOC

Product code: AS110DX


Product name : AS110DX

- USB 3.0 Hub
- Gas Spring
- VESA 75x75mm, 100x100mm
- Weight capacity range (each arm) 2 - 9 Kg

AS110DX Get your monitor in the optimum position easily with AS110's mechanical gas-spring arm with integrated USB Hub

AOC AS110DX. Mounting: Clamp/Bolt-through, Maximum weight capacity: 9 kg, Minimum screen size: 33 cm (13"), Maximum screen size: 81.3 cm (32"), Minimum VESA mount: 75 x 75 mm, Maximum VESA mount: 100 x 100 mm. Height adjustment, Swivel angle range: -90 - 90°, Tilt angle range: -45 - 60°.

Product colour: Black

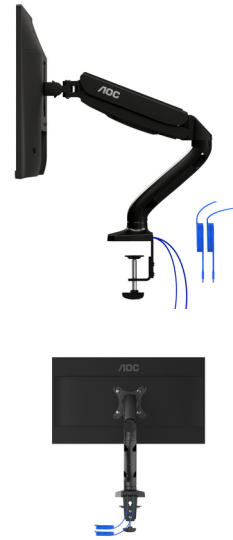

Mounting		Ergonomics	
Maximum weight capacity *	9 kg	Swivel angle range	-90 - 90°
Minimum screen size *	33 cm (13")	Rotating	✓
Number of displays supported *	1	Pivot angle	0 - 360°
Maximum weight capacity (per display) *	9 kg	Cable management	✓
Maximum screen size *	81.3 cm (32")	Design	
Mounting	Clamp/Bolt-through	Housing material	Aluminium
Mounting type *	Desk	Product colour *	Black
Minimum VESA mount *	75 x 75 mm	Ports & interfaces	
Maximum VESA mount *	100 x 100 mm	Built-in USB hub	✓
Panel mounting interface	100 x 100, 75 x 75 mm	USB hub version	3.2 Gen 1 (3.1 Gen 1)
Desk thickness (min)	1.5 cm	Weight & dimensions	
Desk thickness (max)	8 cm	Weight	2.65 kg
Clamp mount desk thickness (max)	8 cm	Packaging data	
Grommet mount desk thickness (max)	8 cm	Package width	280 mm
Mounting hole range	7 - 87 mm	Package depth	410 mm
Ergonomics		Package height	120 mm
Height adjustment	✓	Package weight	2.9 kg
Height adjustment type	Gas spring	Packaging content	
Height adjustment range	320 - 440 mm	Clamp included	✓
Depth adjustment range	0 - 460 mm	Mounting kit	✓
Tilt adjustment	✓	Manual	✓
Tilt angle range	-45 - 60°	Packaging content	User Manual, Monitor Arm, Clamp mount, Grommet mount, Installation materials
Swivelling	✓	Other features	
		Height (max)	58 cm
		Warranty period	5 year(s)



4038986630658

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.