

Targus DOCK116GLZ laptop dock/port replicator Wired USB 3.2 Gen 2 (3.1 Gen 2) Type-C Black

Brand : Targus

Product code: DOCK116GLZ

Product name : DOCK116GLZ

- Truly universal compatibility with DisplayLink® technology
- Integrated lock slot accommodates standard security locks to safeguard equipment
- Windows®, macOS®, ChromeOS™, Android®, Ubuntu™
- TAA Compliant
- Industry-leading 3-year warranty

USB 3.2 G2, 80W, HDMI, 4.13" x 4.13" x 1.13", Black

Targus DOCK116GLZ. Connectivity technology: Wired, Host interface: USB 3.2 Gen 2 (3.1 Gen 2) Type-C, USB Power Delivery up to: 80 W. Product colour: Black, Data transfer rate: 10 Gbit/s, HD type: HD. Power source type: USB, Power connector: USB Type-C. Mobile operating systems supported: Android, Other operating systems supported: ChromeOS. Width: 105 mm, Depth: 105 mm, Height: 28 mm



Ports & interfaces		Performance	
Connectivity technology *	Wired	Cable lock slot type	Kensington
Host interface *	USB 3.2 Gen 2 (3.1 Gen 2) Type-C	Product colour *	Black
USB 3.2 Gen 1 (3.1 Gen 1) Type-A ports quantity *	2	Power	
USB 3.2 Gen 2 (3.1 Gen 2) Type-C ports quantity	2	Power source type	USB
USB Power Delivery (USB PD)	✓	Power connector	USB Type-C
USB Power Delivery revision	3.0	Wireless charging	✗
USB Power Delivery up to	80 W	Software	
HDMI ports quantity *	2	Windows operating systems supported	✓
HDMI version	1.4	Mac operating systems supported	✓
Microphone in *	✗	Mobile operating systems supported	Android
DC-in jack	✗	Other operating systems supported	ChromeOS
Network		Weight & dimensions	
Ethernet LAN *	✓	Width	105 mm
Ethernet LAN (RJ-45) ports	1	Depth	105 mm
Performance		Height	28 mm
Card reader integrated *	✗	Weight	199 g
Data transfer rate	10 Gbit/s	Packaging data	
HD type	HD	Quantity per pack	1 pc(s)
Maximum refresh rate	60 Hz		
Cable lock slot	✓		




0092636360245



092636360245



5051794040326

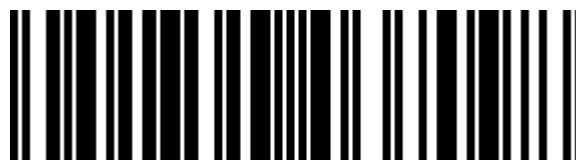

5051794037098



5051794037159

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.