

Viewsonic TD3207 computer monitor 81.3 cm (32") 1920 x 1080 pixels Full HD LED Touchscreen

Brand : Viewsonic

Product code: TD3207

Product name : TD3207

- SuperClear ® AMVA technology

- Long-lasting usage


- Supreme reliability and durability

32", VA, FHD, 1920 x 1080, 3000:1, LED, 450mits, 8bit, 5ms

Viewsonic TD3207. Display diagonal: 81.3 cm (32"), Display resolution: 1920 x 1080 pixels, HD type: Full


HD, Display technology: LED, Response time: 5 ms, Native aspect ratio: 16:9, Viewing angle, horizontal:

178°, Viewing angle, vertical: 178°. Built-in speaker(s). VESA mounting

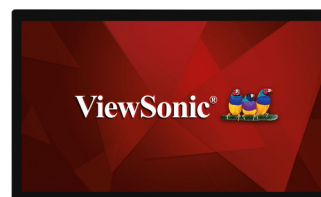

Display		Ports & interfaces	
Display diagonal *	81.3 cm (32")	RS-232 ports	1
Display resolution *	1920 x 1080 pixels	Ergonomics	
HD type *	Full HD	VESA mounting *	✓
Native aspect ratio *	16:9	Power	
Display technology *	LED	Energy efficiency class (SDR) *	E
Panel type *	VA	Energy consumption (SDR) per 1000 hours *	25.8 kWh
LED backlight	✓	Power consumption (typical) *	43 W
Backlight type	LED	Power consumption (standby) *	0.5 W
Touchscreen *	✓	Power consumption (max)	45.5 W
Touchscreen technology	Capacitive	AC input voltage	100 - 240 V
Touch technology	Multi-touch	AC input frequency	50 - 60 Hz
Number of simultaneous touchpoints	10	Power supply type	AC
Display brightness	450 cd/m²	Energy efficiency scale	A to G
Response time *	5 ms	Operational conditions	
Screen shape *	Flat	Operating temperature (T-T)	0 - 40 °C
Contrast ratio (typical) *	3000:1	Operating relative humidity (H-H)	20 - 90%
Contrast ratio (dynamic)	50000000:1	Weight & dimensions	
Maximum refresh rate *	60 Hz	Width (with stand)	747 mm
Viewing angle, horizontal	178°	Depth (with stand)	451 mm
Viewing angle, vertical	178°	Height (with stand)	64 mm
Display number of colours *	16.78 million colours	Weight (with stand)	12.8 kg
Pixel pitch	0.364 x 0.364 mm	Width (without stand)	747 mm
Horizontal scan range	15 - 73 kHz	Depth (without stand)	451 mm
Vertical scan range	47 - 75 Hz	Height (without stand)	64 mm
Digital horizontal frequency	15 - 73 kHz	Weight (without stand)	12.8 kg
Digital vertical frequency	47 - 75 Hz	Packaging data	
Surface hardness	7H	Package width	863 mm
Colour gamut standard	NTSC	Package depth	163 mm
Colour gamut	72%	Package height	577 mm
Performance		Package weight	15.5 kg
NVIDIA G-SYNC *	✗		
AMD FreeSync *	✗		

Multimedia		Other features	
Number of speakers	2	International Protection (IP) code	IP54
Built-in speaker(s) *	✓	Weight	12.8 kg
Design		Certification	Regulations: CE, CE EMC, CB, RoHS, ErP, REACH, WEEE, EAC, UkrSEPRO, UKCA
Glass thickness	3 mm		
Ports & interfaces		Logistics data	
USB upstream port type	USB Type-B	Products per master (outer) case	1 pc(s)
Number of upstream ports	1	Pallet gross width	120 cm
HDMI *	✓	Pallet gross length	100 cm
HDMI ports quantity	1	Pallet gross height	187 cm
HDMI version	1.4	Harmonized System (HS) code	8528521000
DisplayPorts quantity	1		
Audio output	1		

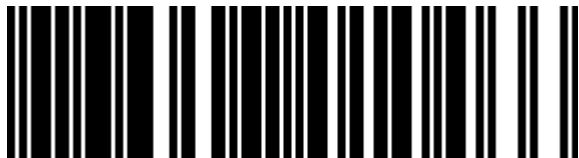

0766907010466



766907010466

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.