



APC EPDU1216S power distribution unit (PDU) 27 AC outlet(s) 0U Black

Brand : APC

Product code: EPDU1216S

Product name : EPDU1216S

EasyPDU, Switched, Zero U, 11 kW, 230V, 21 x C13 & 6 x C19 Out


[APC EPDU1216S power distribution unit \(PDU\) 27 AC outlet\(s\) 0U Black:](#)

Easy Switched Rack Power Distribution Units (Rack PDU) provide on/off outlet switching, advanced power management, load monitoring and much more features than the average power strip.

APC EPDU1216S. PDU types: Switched, Rack capacity: 0U, Type: Three-phase. AC outlets quantity: 27 AC outlet(s), AC outlet types: C13 coupler, C19 coupler, Power plug: IEC 60309. Cable length: 2 m. Nominal input voltage: 400 V, Maximum current: 16 A, AC input frequency: 50 - 60 Hz. Compliance certificates: CE, Certification: CE, EAC, RCM, TÜV



Design		Certificates	
PDU types *	Switched	Certification	CE, EAC, RCM, TÜV
Type	Three-phase	Sustainability	
Rack capacity *	0U	Sustainability compliance	✓
Mounting	Vertical	Operational conditions	
Housing material	Aluminium	Operating temperature (T-T)	-5 - 45 °C
Product colour	Black	Storage temperature (T-T)	-25 - 65 °C
Ports & interfaces		Operating relative humidity (H-H)	5 - 95%
AC outlets quantity *	27 AC outlet(s)	Storage relative humidity (H-H)	5 - 95%
Power plug	IEC 60309	Operating altitude	0 - 3000 m
AC outlet types *	C13 coupler, C19 coupler	Non-operating altitude	0 - 15000 m
Features		Weight & dimensions	
Daisy chain	✓	Width	55 mm
Cable length	2 m	Depth	62 mm
Power		Height	1794 mm
Nominal input voltage *	400 V	Weight	6.2 kg
AC input frequency	50 - 60 Hz	Packaging data	
Maximum current *	16 A	Package weight	7.78 kg
Output voltage	230 V	Package width	160 mm
Maximum power	11000 W	Package depth	110 mm
Certificates		Package height	1950 mm
Compliance certificates	CE		

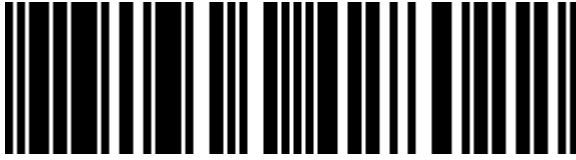

0731304428022



731304428022

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.