

ASUS F1 Standard throw projector DLP 1080p (1920x1080) Black

Brand : ASUS

Product code: 90LJ00B0-B00520

Product name : F1

- 1200-lumen long-life LED light source for best-in-class Full HD visuals
- Short-throw lens lets it project images measuring from 25-inch (0.45m) to 210-inch (3.7m)
- High-fidelity 2.1-channel audio with Harman Kardon® audio technology
- Horizontal and vertical keystone adjustment as well as autofocus ensures sharp and distortion-free images

- Wireless projection lets you effortlessly stream content from smartphone, tablet or other mobile devices for high-definition entertainment or presentations anywhere


0.47" DLP, R/G/B LED, 100%(NTSC), HDMI x2, D-sub, 1 x Type A, 3.5mm Mini-Jack

ASUS F1. Projection technology: DLP, Projector native resolution: 1080p (1920x1080), Contrast ratio (typical): 3500:1. Noise level: 32 dB. Product type: Standard throw projector, Market positioning:

Portable, Product colour: Black. Power source: AC. Weight: 1.8 kg, Width: 250 mm, Depth: 210 mm



Projector		Features	
Supported aspect ratios	16:9	Noise level *	32 dB
Projection technology *	DLP	Design	
Projector native resolution *	1080p (1920x1080)	Market positioning *	Portable
Contrast ratio (typical) *	3500:1	Product type *	Standard throw projector
Native aspect ratio *	16:9	Product colour *	Black
Number of colours	16.78 million colours	LED indicators	✓
Video		Power	
Full HD *	✓	Power source *	AC
Ports & interfaces		Weight & dimensions	
USB 2.0 ports quantity	1	Width	250 mm
Headphone outputs	1	Depth	210 mm
VGA (D-Sub) ports quantity *	1	Height	75 mm
HDMI ports quantity *	2	Weight *	1.8 kg
DVI port *	✗	Packaging content	
Network		Remote control included *	✓
Ethernet LAN *	✗	Logistics data	
Wi-Fi *	✗	Harmonized System (HS) code	85286200

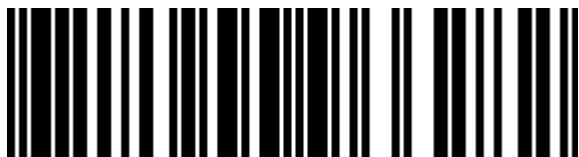

4712900966282



0192876091906



192876091906



4718017091879

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.