




## BenQ SL5502K Digital signage flat panel 139.7 cm (55") LED 500 cd/m² 4K Ultra HD Black Android 24/7

**Brand :** BenQ

**Product code:** 9H.F67PK.NA6

**Product name :** SL5502K

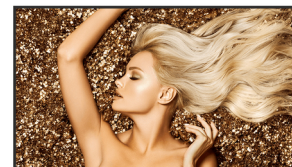

55" Smart Signage Series, E-LED, 3840 x 2160, 500cd/m2, 24 / 7, Landscape / Portrait  
BenQ SL5502K. Product design: Digital signage flat panel. Display diagonal: 139.7 cm (55"), Display technology: LED, Display resolution: 3840 x 2160 pixels, Display brightness: 500 cd/m², HD type: 4K Ultra HD. Operating hours (hours/days): 24/7. Operating system installed: Android. Product colour: Black



| Display                     |                    | Performance                             |                                                                                                                                                                                                                                         |
|-----------------------------|--------------------|-----------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| LED backlighting type       | Edge-LED           | Purpose *                               | Universal                                                                                                                                                                                                                               |
| Display diagonal *          | 139.7 cm (55")     | Multi-display supported                 | ✓                                                                                                                                                                                                                                       |
| Display technology *        | LED                | On Screen Display (OSD)                 | ✓                                                                                                                                                                                                                                       |
| Display resolution *        | 3840 x 2160 pixels | Number of OSD languages                 | 26                                                                                                                                                                                                                                      |
| Display brightness *        | 500 cd/m²          |                                         | Simplified Chinese, Traditional Chinese, Czech, Danish, German, Dutch, English, Spanish, Finnish, French, Hungarian, Italian, Japanese, Korean, Norwegian, Persian, Polish, Portuguese, Romanian, Russian, Swedish, Turkish, Vietnamese |
| HD type *                   | 4K Ultra HD        | On Screen Display (OSD) languages       |                                                                                                                                                                                                                                         |
| Touchscreen *               | ✗                  | Operating hours (hours/days)            | 24/7                                                                                                                                                                                                                                    |
| Native aspect ratio         | 16:9               |                                         |                                                                                                                                                                                                                                         |
| Contrast ratio (typical)    | 1200:1             |                                         |                                                                                                                                                                                                                                         |
| Viewing angle, horizontal   | 178°               |                                         |                                                                                                                                                                                                                                         |
| Viewing angle, vertical     | 178°               |                                         |                                                                                                                                                                                                                                         |
| Active display area (W x H) | 1209.6 x 680.4 mm  |                                         |                                                                                                                                                                                                                                         |
| Panel life                  | 50000 h            |                                         |                                                                                                                                                                                                                                         |
| Ports & interfaces          |                    | Power                                   |                                                                                                                                                                                                                                         |
| HDMI ports quantity *       | 2                  | Power consumption (typical) *           | 85.6 W                                                                                                                                                                                                                                  |
| HDMI input ports quantity   | 2                  | Power consumption (standby) *           | 0.5 W                                                                                                                                                                                                                                   |
| DVI port *                  | ✗                  | Energy efficiency class (SDR)           | G                                                                                                                                                                                                                                       |
| VGA (D-Sub) input ports     | 1                  | Energy consumption (SDR) per 1000 hours | 86 kWh                                                                                                                                                                                                                                  |
| DisplayPorts quantity *     | 1                  | AC input voltage                        | 100 - 240 V                                                                                                                                                                                                                             |
| USB port *                  | ✓                  | AC input frequency                      | 50 - 60 Hz                                                                                                                                                                                                                              |
| USB ports quantity          | 4                  | Energy efficiency scale                 | A to G                                                                                                                                                                                                                                  |
| Ethernet LAN (RJ-45) ports  | 1                  |                                         |                                                                                                                                                                                                                                         |
| RS-232 interface            | ✓                  |                                         |                                                                                                                                                                                                                                         |
| Audio                       |                    | Computer system                         |                                                                                                                                                                                                                                         |
| Built-in speaker(s) *       | ✓                  | Internal memory                         | 4 GB                                                                                                                                                                                                                                    |
| Number of built-in speakers | 2                  | Internal storage capacity               | 32 GB                                                                                                                                                                                                                                   |
| RMS rated power             | 20 W               | Operating system installed              | Android                                                                                                                                                                                                                                 |
|                             |                    | Weight & dimensions                     |                                                                                                                                                                                                                                         |
|                             |                    | Width                                   | 1236.4 mm                                                                                                                                                                                                                               |
|                             |                    | Depth                                   | 63.1 mm                                                                                                                                                                                                                                 |

| Design                   |                            | Weight & dimensions         |             |
|--------------------------|----------------------------|-----------------------------|-------------|
| Product design *         | Digital signage flat panel | Height                      | 707.2 mm    |
| Placement supported *    | Indoor                     | Weight                      | 26.4 kg     |
| Orientation              | Horizontal/Vertical        | Packaging data              |             |
| Product colour *         | Black                      | Package weight              | 31.4 kg     |
| VESA mounting *          | ✓                          | Packaging content           |             |
| Panel mounting interface | 400 x 400 mm               | Remote control included     | ✓           |
| Bezel width (bottom)     | 1.18 cm                    | Remote control type         | IR          |
| Bezel width (side)       | 1.18 cm                    | Cables included             | HDMI, VGA   |
| Bezel width (top)        | 1.18 cm                    | Operational conditions      |             |
|                          |                            | Operating temperature (T-T) | 0 - 40 °C   |
|                          |                            | Storage temperature (T-T)   | -10 - 60 °C |
|                          |                            | Logistics data              |             |
|                          |                            | Harmonized System (HS) code | 85285210    |
|                          |                            | Network                     |             |
|                          |                            | Ethernet LAN *              | ✓           |



5054444364827

### **Catalog Object Cloud**



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.