

StarTech.com 10 ft 2-in-1 Universal USB KVM Cable

Brand : StarTech.comProduct code: SVUSB2N1_10

Product name : 10 ft 2-in-1 Universal USB KVM Cable

StarTech.com 10 ft 2-in-1 Universal USB KVM Cable - 10ft VGA KVM Cable - 10ft USB KVM Cable - 10ft KVM Switch Cable

StarTech.com 10 ft 2-in-1 Universal USB KVM Cable:

The SVUSB2N1_10 10ft 2-in-1 USB + VGA KVM switch Cable is constructed of high quality materials and is expertly designed to ensure crystal clear display quality, and reliable connections.

Our universal USB KVM switch cables prevent tangles and keep your workspace neat, while delivering excellent performance with your StarTech.com or other KVM switch.

Works with:
Compatible StarTech.com KVMs can be found under the Accessories section.
Aten models (CS102U, CS104U)
Belkin models (F1DN102U, F1DN104U, F1DN108U)
TrippLite models (B006-004-R)
Cables to go models (35555, 35566, 35554, 52064)
IOGear models (GCS102U, GCS104U)

Backed by a StarTech.com lifetime warranty.

The StarTech.com Advantage

- Unique design minimizes the number of cables required



Performance		Performance	
Product colour	Black	Compatible products	Aten - CS102U, CS104U Belkin - F1DN102U, F1DN104U, F1DN108U
Cable length *	3 m		Tripplite - B006-004-R Cables to go - 35555, 35566, 35554, 52064
Keyboard port type *	USB		IOGear - GCS102U, GCS104U
Mouse port type *	USB	Certificates	
Video port type *	VGA	Compliance certificates	RoHS
Connector 1	USB A + VGA	Packaging data	
Connector 2	USB B + VGA	Weight	440 g
Connector 1 gender	Male	Package width	140 mm
Connector 2 gender	Male/Female	Package depth	400 mm
		Package height	26 mm
		Package weight	449 g
		Logistics data	
		Harmonized System (HS) code	84733080



0065030788649




065030788649



0064780864207




064780864207

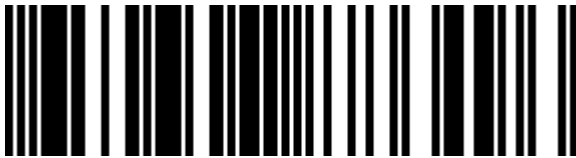

0650307886496



650307886496

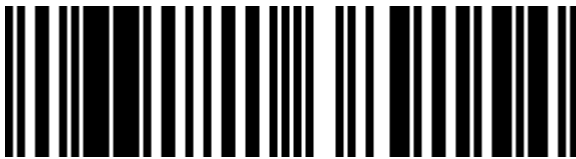

0163121389154



163121389154

Catalog Object Cloud



Disclaimer: The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.