



HyperX Pulsefire Mat - RGB Gaming Mousepad - Cloth (XL)

Brand : HyperX

Product family: HyperX

Product code: 457T2AA

Product name : HyperX
Pulsefire Mat - RGB Gaming
Mousepad - Cloth (XL)




HyperX Pulsefire Mat - RGB Gaming Mousepad - Cloth (XL)

[HyperX Pulsefire Mat - RGB Gaming Mousepad - Cloth \(XL\):](#)

Roll out stunning RGB lighting and precision tracking.

The HyperX Pulsefire Mat RGB Mouse Pad is built for the gamer that loves extra flair, but still needs their mouse pad to provide a smooth, precise mouse surface. Give your setup an extra pop of eye-catching style with 2 zones of customizable lighting, and a convenient touch selector to switch between lighting profiles. With a durable, densely-woven precision surface and an anti-slip rubber underside, Pulsefire Mat ensures that your mouse pad will enhance both your gaming and glamour. The flat surface provides a smooth, consistent mouse glide and it rolls up for easy portability. Customize lighting and smooth lighting effects with HyperX NGENUITY software, and save you profiles directly to the onboard memory.

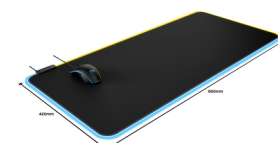

Performance		Packaging data	
Surface coloration *	Monochromatic	Quantity per pack	1 pc(s)
Material	Cloth, Rubber	Package width	111 mm
Gaming mouse pad *	✓	Package depth	110 mm
Wrist rest *	✗	Package height	461 mm
Non-slip base	✓	Package weight	1.18 kg
LED backlight	✓	Sustainability	
Number of light modes	2	Sustainability compliance	✓
Product colour *	Black	Technical details	
Weight & dimensions		Box contents	Mouse Pad
Width *	420 mm	General Product Safety Regulation (GPSR) URL	https://kaas.hpcloud.hp.com/pdf-public/pdf_8666243_en-US-1.pdf https://row.hyperx.com/pages/limited-warranty-statement
Depth *	900 mm	Other features	
Thickness	4 mm	Country of origin	China
Weight	1 kg	Logistics data	
Cable length	1.8 m	UNSPSC-code	43211802
Height	4 mm	Harmonized System (HS) code	84733080



0196188239384



196188239384



5704174984955

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.