




QNAP QM2-2P2G2T network card Internal Ethernet 2500 Mbit/s

Brand : QNAP

Product code: QM2-2P2G2T


Product name : QM2-2P2G2T

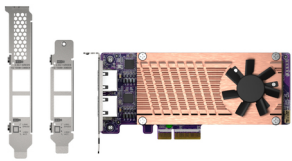

2x 2.5GBASE-T, 2 x M.2 2280, PCIe Gen3 x4, 152.65x68.9x20.6 mm

QNAP QM2-2P2G2T network card Internal Ethernet 2500 Mbit/s:

 The QM2-2P2G2T adds support for M.2 SSDs and 2.5GbE connectivity to your QNAP NAS. Combining M.2 SSD and 2.5GbE connectivity into one solution, the QM2 PCIe expansion card improves overall NAS performance by enabling SSD caching while providing an affordable upgrade path for adopting 2.5GbE networks. As a PCIe card, the QM2-2P2G2T does not occupy any 3.5-inch drive bays, allowing you to upgrade your NAS without impacting your potential storage capacity.



Future-proof your network environments

The QM2-2P2G2T QM2 PCIe card also features dual 2.5GBASE-T Multi-Gigabit (2.5G/1G/100M/10M) network ports to empower your NAS/computer/server with high-speed 2.5GbE connectivity for bandwidth-demanding tasks.

QNAP QM2-2P2G2T. Internal. Connectivity technology: Wired, Host interface: PCI Express, Interface: Ethernet. Maximum data transfer rate: 2500 Mbit/s

Ports & interfaces		Design	
Connectivity technology *	Wired	Internal *	✓
Host interface *	PCI Express	Weight & dimensions	
Interface *	Ethernet	Width	68.9 mm
Ethernet LAN (RJ-45) ports	2	Depth	152.7 mm
Network		Height	20.6 mm
Maximum data transfer rate *	2500 Mbit/s	Packaging content	
Design		Mounting brackets included	✓
Component for *	NAS	Logistics data	
		Harmonized System (HS) code	85176990



4713213519073



0885022021277



885022021277

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.