



Lenovo DB610S Gigabit Ethernet (10/100/1000) 1U Black




Brand : Lenovo **Product code:** 7D8PA002WW

Product name : DB610S

ThinkSystem DB610S, ENT Bundle, 24 ports licensed, 24x 16Gb SWL SFPs, 1 PS, Rail Kit
Lenovo DB610S. Basic switching RJ-45 Ethernet ports type: Gigabit Ethernet (10/100/1000), Basic switching RJ-45 Ethernet ports quantity: 2, Installed SFP+ modules quantity: 8, USB 2.0 ports quantity: 1. Full duplex. Switching capacity: 28.05 Gbit/s. Power connector: AC-in jack. Rack mounting, Form factor: 1U

Ports & interfaces		Design	
Basic switching RJ-45 Ethernet ports quantity *	2	Number of fans	4 fan(s)
Basic switching RJ-45 Ethernet ports type *	Gigabit Ethernet (10/100/1000)	Power	
Installed SFP+ modules quantity *	8	Power source *	AC
SFP+ module slots quantity	24	Power supply included *	✓
USB 2.0 ports quantity	1	Number of power supply units	1
Power connector	AC-in jack	AC input voltage	100 - 240 V
Network		AC input frequency	50 - 60 Hz
10G support *	✓	Power consumption (typical)	150 W
Port mirroring	✓	Other features	
Full duplex	✓	Power supply	150 W
Data transmission		Operational conditions	
Switching capacity *	28.05 Gbit/s	Operating temperature (T-T)	0 - 40 °C
Throughput	768000 Mpps	Storage temperature (T-T)	-20 - 70 °C
Security		Operating relative humidity (H-H)	10 - 85%
Access Control List (ACL)	✓	Storage relative humidity (H-H)	10 - 90%
Security algorithms	802.1x RADIUS, IPSec, SSH, SSL/TLS	Operating altitude	0 - 3000 m
SSH/SSL support	✓	Non-operating altitude	0 - 12000 m
Multicast features		Weight & dimensions	
Multicast support	✓	Width	429 mm
Design		Depth	307 mm
Rack mounting *	✓	Height	43 mm
Form factor	1U	Weight	42 kg
Product colour	Black	Logistics data	
		Harmonized System (HS) code	85176990

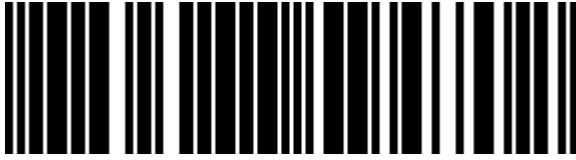

0889488594702



889488594702

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.