



TP-Link TD-W9960 wireless router Single-band (2.4 GHz) White

Brand : TP-Link

Product code: TD-W9960

Product name : TD-W9960



- Versatile Connectivity – With DSL and LAN/WAN ports, TD-W9960 is fully compatible with the VDSL2/ADSL2+/ADSL2/ADSL standards and also works with fiber/cable access

- Boosted Speeds – Superfast VDSL broadband speeds of up to 100Mbps together with 300Mbps Wi-Fi

- Maximized Range – Powerful external antennas provide far-reaching wireless coverage in every direction


- Effortless Management – Set up in minutes with the powerful Tether app or intuitive web interface and manage the network from anywhere

4x RJ-45, RJ-11, IEEE 802.11 b/g/n, 300 Mbps, 2x 5dBi, White

TP-Link TD-W9960. WAN connection type: RJ-45. Wi-Fi band: Single-band (2.4 GHz), Top Wi-Fi standard: Wi-Fi 4 (802.11n), WLAN data transfer rate (max): 300 Mbit/s. Supported network protocols: IPv4, IPv6.

Product type: Tabletop router, Product colour: White, LED indicators: LAN, Status, WLAN. Antenna design: External, Antenna gain level (max): 5 dBi

WAN connection		Design	
Ethernet WAN *	✓	Product colour	White
DSL WAN *	✓	Wall mountable	✓
SIM card slot *	✗	LED indicators	LAN, Status, WLAN
3G/4G USB modem compatibility *	✗	On/off switch	✓
WAN connection type	RJ-45	Product type *	Tabletop router
Wireless LAN features		Packaging content	
Wi-Fi band *	Single-band (2.4 GHz)	Quick installation guide	✓
Top Wi-Fi standard *	Wi-Fi 4 (802.11n)	Antenna	
WLAN data transfer rate (max) *	300 Mbit/s	Antenna design *	External
Wi-Fi standards	802.11b, 802.11g, Wi-Fi 4 (802.11n)	Antenna gain level (max)	5 dBi
Protocols		Antennas quantity	2
Supported network protocols	IPv4, IPv6	Logistics data	
		Products per pallet	1 pc(s)

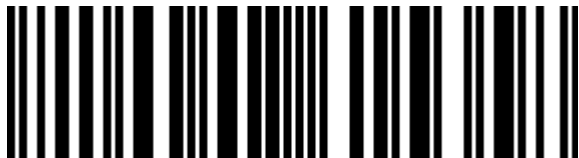

1210002615358

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.