



APC BE650G2-FR uninterruptible power supply (UPS) Standby (Offline) 0.65 kVA 400 W

Brand : APC

Product code: BE650G2-FR


Product name : BE650G2-FR



- APC Back-UPS 650VA, 230V, 1USB charging port
- Battery Backup & Surge Protector for Electronics and Computers
- Includes: User Manual

Back-UPS, 400W, 650VA, 230V, 1x USB, 47/63 Hz

APC BE650G2-FR. UPS topology: Standby (Offline), Output power capacity: 0.65 kVA, Output power: 400 W. AC outlet types: Type E, Cabling technology: 10/100Base-T. Battery life (max): 5 year(s), Battery recharge time: 16 h. Form factor: Compact, Product colour: Black, Cable length: 1.83 m. Compliance certificates: RoHS, Certification: CE, EAC

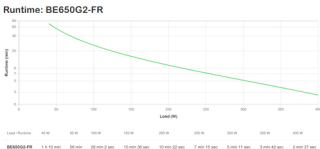

Features		Battery	
UPS topology *	Standby (Offline)	Automatic battery test	✓
Output power capacity *	0.65 kVA	Cold start	✓
Output power *	400 W	Design	
Waveform *	Sine	Form factor *	Compact
Input operation voltage (min) *	220 V	Cable length	1.83 m
Input operation voltage (max) *	230 V	Product colour *	Black
Input frequency *	47/63 Hz	LED indicators	✓
Output operation voltage (min)	220 V	Operational conditions	
Output operation voltage (max)	230 V	Operating temperature (T-T)	0 - 40 °C
Output frequency	47/63 Hz	Storage temperature (T-T)	-15 - 45 °C
Maximum current	6 A	Operating relative humidity (H-H)	0 - 90%
Surge energy rating	310 J	Storage relative humidity (H-H)	0 - 95%
Efficiency	80%	Non-operating altitude	0 - 4500 m
Noise level	45 dB	Certificates	
Surge protection	✓	Compliance certificates	RoHS
Surge protection features	Digital Subscriber Line (DSL)	Certification	CE, EAC
Audible alarm(s)	✓	Packaging content	
Audible alarm modes	Alarm when on battery, Low battery alarm, Overload alarm	Management card included	✗
Ports & interfaces		Manual	✓
AC outlet types	Type E	Weight & dimensions	
USB port	✓	Width	130 mm
Ethernet LAN (RJ-45) ports	1	Depth	365 mm
Cabling technology	10/100Base-T	Height	120 mm
SmartSlot	✗	Weight	4 kg
SmartConnect port	✗	Packaging data	
Battery		Package width	186 mm
Battery life (max)	5 year(s)	Package depth	441 mm
Battery recharge time	16 h	Package height	190 mm
Hot-swap battery	✓	Package weight	4.5 kg

Logistics data

Harmonized System (HS) code	85078000
-----------------------------	----------



0731304347200



731304347200

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.