

Viewsonic IFP9850-4 Signage Display Interactive flat panel 2.49 m (98") LCD Wi-Fi 350 cd/m² 4K Ultra HD Black Touchscreen Built-in processor Android 9


Brand : Viewsonic

Product code: IFP9850-4

Product name : IFP9850-4


- Natural pen-on-paper writing experience with Ultra Fine Touch technology
 - Seamless plug-and-present connectivity via USB-C
 - Native whiteboarding software for seamless annotation and collaboration
 - Wireless content sharing and 4-way split screen for multiple contributors
 - myViewBoard Manager for simplified and centralized display management
- 98", TFT LCD, 16:9, 2171.85 x 1232.35, 3840 x 2160p, 1.07B colors, 350nits, 3000:1, 8ms, 30000h, Anti-glare, 4GB DDR4, 32GB, HDMI 2.0, RGB/VGA, RS232, WIFI, 3.5mm, SPDIF, RJ-45 x2, USB Type-A 3.0/2.0, 16Wx2, Android 9, 103.6kg, 2245 x 1323 x 91 mm

Viewsonic IFP9850-4. Product design: Interactive flat panel. Display diagonal: 2.49 m (98"), Display technology: LCD, Display resolution: 3840 x 2160 pixels, Display brightness: 350 cd/m², HD type: 4K Ultra HD, Touchscreen. Wi-Fi. Operating system installed: Android 9. Product colour: Black

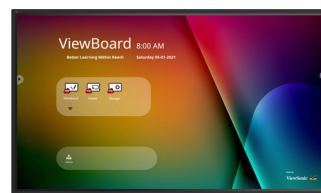

Display		Weight & dimensions	
Panel type	TFT	Width	2245 mm
LED backlight	✓	Depth	91 mm
Display diagonal *	2.49 m (98")	Height	1323 mm
Display technology *	LCD	Weight	103.6 kg
Display resolution *	3840 x 2160 pixels	Packaging data	
Display brightness *	350 cd/m ²	Package width	2406 mm
HD type *	4K Ultra HD	Package depth	280 mm
Touchscreen *	✓	Package height	1474 mm
Native aspect ratio	16:9	Package weight	135.2 kg
Response time	8 ms	Packaging content	
Contrast ratio (typical)	3000:1	Remote control included	✓
Display number of colours	1.07 billion colours	Batteries included	✓
Ports & interfaces		Cables included	HDMI, USB Type-C
HDMI ports quantity *	2	Mounting kit	✓
HDMI version	2.0	Operational conditions	
HDMI output ports quantity	1	Operating temperature (T-T)	0 - 40 °C
USB connector type	USB Type-A, USB Type-B, USB Type-C	Operating relative humidity (H-H)	10 - 90%
Ethernet LAN (RJ-45) ports	2	Logistics data	
Audio		Products per master (outer) case	1 pc(s)
Built-in speaker(s) *	✓	Pallet gross length	114 cm
Number of built-in speakers	2	Pallet gross width	2.5 m
Design		Pallet gross height	162.5 cm
Product design *	Interactive flat panel	Harmonized System (HS) code	8528521000
Product colour *	Black	Sensors	
VESA mounting *	✓	Ambient light sensor	✓
Panel mounting interface	800 x 600 mm	Network	
Anti-glare screen	✓	Wi-Fi *	✓
Power		Features	
Power consumption (typical) *	192.5 W	Wall mountable	✓
Power consumption (off)	0.5 W		
AC input voltage	100 -2 40 V		

Computer system		Other features	
Built-in processor *	✓	Manual	✓
Processor architecture	ARM Cortex-A73	Quick start guide	✓
Processor cores	4	Audio output	1
Operating system installed	Android 9	USB 2.0 ports quantity	2

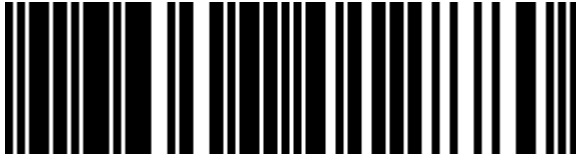

0766907012880



766907012880

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.