

Viewsonic CDE4330 Signage Display 109.2 cm (43") Wi-Fi 450 cd/m² 4K Ultra HD Black Built-in processor Android 11

Brand : Viewsonic


Product code: CDE4330

Product name : CDE4330

- Wireless presentation for upgraded efficiency
- Single cable via USB-C with 65W power delivery
- 24/7 Sustainable video playback for continuous communication
- Remote device management with myViewBoard Manager
- ProAV compatibility with Crestron, Extron, and AMX


43", TFT LCD, 941.184 x 529.416, 3840 x 2160p, 1.07G, 450nits, 1200:1, 6.5ms, 4GB, 32GB, HDMI 2.1 x3, RS-232, WIFI slot, SPDIF x1, RJ45 x1, Type-A 2.0 x 1, 3.0 x1, 10w x 2, Android 11, 100 - 240V, 9.9kg, 964.6 x 552.5 x 71.4mm

Viewsonic CDE4330. Display diagonal: 109.2 cm (43"), Display resolution: 3840 x 2160 pixels, Display brightness: 450 cd/m², HD type: 4K Ultra HD. Wi-Fi. Operating system installed: Android 11. Product colour: Black

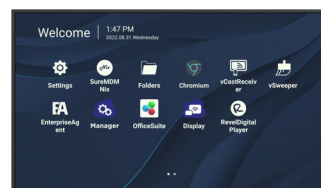

Display		Power	
Panel type	TFT	AC input voltage	100 - 240 V
LED backlighting type	Direct-LED	Energy efficiency scale	A to G
Display diagonal *	109.2 cm (43")	Computer system	
Display resolution *	3840 x 2160 pixels	Built-in processor *	✓
Display brightness *	450 cd/m ²	Processor architecture	ARM Cortex-A55
HD type *	4K Ultra HD	Processor cores	4
Touchscreen *	✗	Operating system installed	Android 11
Native aspect ratio	16:9	Weight & dimensions	
Response time	6.5 ms	Display width	964.6 mm
Contrast ratio (typical)	1200:1	Display depth	71.4 mm
Contrast ratio (dynamic)	5000:1	Display height	552.6 mm
Display number of colours	1.07 billion colours	Display weight	9.9 kg
Ports & interfaces		Weight	9.9 kg
HDMI ports quantity *	4	Packaging data	
HDMI version	2.1	Package width	1056 mm
HDMI output ports quantity	1	Package depth	156 mm
DisplayPort version	1.2	Package height	672 mm
USB connector type	USB Type-A	Package weight	13.8 kg
USB 3.2 Gen 1 (3.1 Gen 1) Type-A ports quantity	1	Packaging content	
USB Power Delivery (USB PD)	✓	Remote control included	✓
USB Power Delivery up to	65 W	Cables included	HDMI, Power, RS-232, USB Type-C
USB Type-C DisplayPort Alternate Mode	✓	Mounting kit	✓
Ethernet LAN (RJ-45) ports	1	Operational conditions	
Audio		Operating temperature (T-T)	0 - 40 °C
Built-in speaker(s) *	✓	Operating relative humidity (H-H)	10 - 90%
Number of built-in speakers	2	Logistics data	
Design		Products per master (outer) case	1 pc(s)
Product colour *	Black	Pallet gross length	114 cm
VESA mounting *	✓	Pallet gross width	108 cm
Panel mounting interface	200 x 200 mm	Pallet gross height	79.9 cm

Design		Logistics data	
Anti-glare screen	✓	Harmonized System (HS) code	8528521000
Power		Network	
Power consumption (typical) *	75 W	Wi-Fi *	✓
Power consumption (off)	0.5 W	Technical details	
Energy efficiency class (SDR)	G	OPS slot	1
Energy consumption (SDR) per 1000 hours	112 kWh	Other features	
		User memory	32 GB
		Manual	✓
		USB 2.0 ports quantity	1

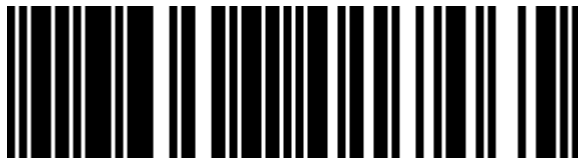

0766907017465



766907017465

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.