

Viewsonic VB-CAM-201-2 video conferencing camera 8.51 MP Black 2160 x 1080 pixels 30 fps CMOS 25.4 / 2.5 mm (1 / 2.5")



Brand : Viewsonic


Product code: VB-CAM-201-2

Product name : VB-CAM-201-2

- Zoom Rooms Certified Camera
- Automatically focus framing on narrator during the conference through voice tracking
- Automatically adjust the frame based on attendees' seating with up to 121° wide-angle FOV
- 4K UHD resolution and 5x digital zooming
- Multiple mounting options to fit in all meeting room setups
- Stereo speaker and 4 array microphone with 3A audio (AEC/ANS/AGC) processing technology*

1/2.5 inch, CMOS, 8.51M pixel, 600 x 115 x 135 mm, 2.2 kg
Viewsonic VB-CAM-201-2. Megapixel (approx.): 8.51 MP, Sensor type: CMOS. HD type: 4K Ultra HD, Maximum video resolution: 2160 x 1080 pixels, Supported video modes: 720p, 1080p, 2160p, Maximum frame rate: 30 fps. Field of view (FOV) angle: 121°, Digital zoom: 5x. Mounting type: Stand, Product colour: Black

Camera		Ports & interfaces	
Camera type	Single camera	Ethernet LAN (RJ-45) ports	1
Megapixel (approx.) *	8.51 MP	DC-in jack	✓
Sensor type	CMOS	Microphone in	✓
Optical sensor size	25.4 / 2.5 mm (1 / 2.5")	System requirements	
Effective sensor resolution	8.51 MP	Windows operating systems supported	Windows 10, Windows 7, Windows 8.1
Zoom capability	✓	Mac operating systems supported	Mac OS X 10.10 Yosemite
Digital zoom	5x	Performance	
Field of view (FOV) angle	121°	Certification	CE, FCC, IC ID, FCC ID, LVD
White balance	Auto, Indoor, Manual, One push, Outdoor	Logistics data	
3D NR (Noise Reduction)	✓	Products per master (outer) case	4 pc(s)
Video		Pallet gross length	100 cm
HD type *	4K Ultra HD	Pallet gross width	120 cm
Maximum video resolution *	2160 x 1080 pixels	Pallet gross height	155 cm
Maximum frame rate *	30 fps	Harmonized System (HS) code	8525890000
Supported video modes	720p, 1080p, 2160p	Weight & dimensions	
Video formats supported	H.264, M-JPEG, YUY2	Width	600 mm
Design		Depth	135 mm
Product colour *	Black	Height	115 mm
Mounting type	Stand	Weight	3.7 kg
Tilt angle range	0 - 15°	Packaging data	
Pan range	0 - 15°	Package width	661 mm
Ports & interfaces		Package depth	230 mm
HDMI ports quantity	1	Package height	223 mm
USB 2.0 ports quantity	1	Package weight	4.2 kg
USB 3.2 Gen 1 (3.1 Gen 1) Type-C ports quantity	1		

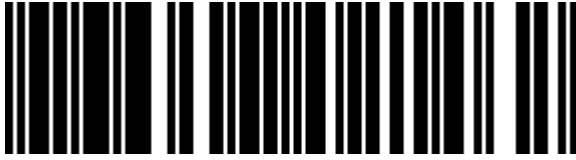

0766907021462



766907021462

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.