



APC Symmetra LX 9 Battery uninterruptible power supply (UPS) 8 kVA 5600 W

Brand : APC

Product code: SYBFXR9RMI

Product name : Symmetra LX 9 Battery



APC Symmetra LX 9 Battery Rack-Mount XR FRAME, 230V, with Enclosed battery cabinet,.

APC Symmetra LX 9 Battery uninterruptible power supply (UPS) 8 kVA 5600 W:

Modular design

- Modular construction - can be deployed as a non-standby and migrate to a standby (UPS) system.

Hot-swappable batteries

- Ensures clean, uninterrupted power to protected equipment while batteries are being replaced

Battery modules connected in parallel

- Delivers higher availability through redundant batteries.

User-replaceable batteries

- Increases availability by allowing a trained user to perform upgrades and replacements of the batteries reducing Mean Time to Repair (MTTR)


Plug-and-Play external batteries

- Ensures clean, uninterrupted power to the loads when adding extra runtime to the UPS.

APC Symmetra LX 9 Battery. Output power capacity: 8 kVA, Output power: 5600 W. Battery technology: Sealed Lead Acid (VRLA). Product colour: Black. Certification: BSMI/EN 50091-1/EN 50091-2/EN 60950/IEC 60950/VCCI/VDE. Weight: 50.9 kg



Features		Operational conditions	
Output power capacity *	8 kVA	Operating relative humidity (H-H)	0 - 95%
Output power *	5600 W	Storage relative humidity (H-H)	0 - 95%
Battery		Certificates	
Battery technology	Sealed Lead Acid (VRLA)	Certification	BSMI/EN 50091-1/EN 50091-2/EN 60950/IEC 60950/VCCI/VDE
Design		Weight & dimensions	
Product colour *	Black	Weight	50.9 kg
LED indicators	✓	Other features	
Operational conditions		Dimensions (WxDxH)	483 x 726 x 602 mm
Operating temperature (T-T)	0 - 40 °C		
Storage temperature (T-T)	-15 - 45 °C		

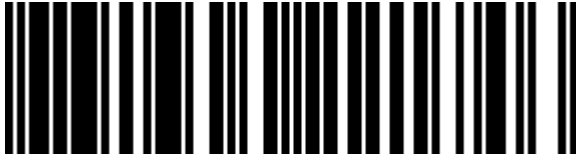

0731304221746



731304221746

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.