

Brother TN-2000 toner cartridge 1 pc(s) Original Black

Brand : Brother

Product code: TN-2000

Product name : TN-2000



- Prints 2,500 pages in accordance with ISO/IEC19798
 - High quality genuine Brother cartridge
 - Prevents waste to save you paper, time and money
- The Brother TN-2000 Black Toner Cartridge. Prints 2,500 pages.


Brother TN-2000 toner cartridge 1 pc(s) Original Black:

With the Genuine Brother TN-2000 Black Toner Cartridge, you can enjoy fast print speeds, increased productivity and high impact graphics every time you print. Formulated in line with Brother's high design specification, the TN-2000 cartridge can produce up to 2,500 vibrant, eye-catching pages.
Brother TN-2000. Black toner page yield: 2500 pages, Printing colours: Black, Quantity per pack: 1 pc(s)

Features		Packaging data	
Compatibility *	DCP-7010, DCP-7010L, FAX-2820, HL-2030, FAX-2920, DCP-7025, HL-2040, HL-2070N, MFC-7225N, MFC-7420, MFC-7820N	Package width	130 mm
Quantity per pack *	1 pc(s)	Package depth	363 mm
Black toner page yield *	2500 pages	Package height	170 mm
Type *	Original	Package weight	1.03 kg
Printing colours *	Black	Other features	
Brand compatibility *	Brother	Print technology	Laser printing
Product colour	Black	Logistics data	
Country of origin	China	Harmonized System (HS) code	84439990
Weight & dimensions		Master (outer) cases per pallet layer	6 pc(s)
Width	166 mm	Master (outer) cases per pallet	72 pc(s)
Depth	125 mm	Layers per pallet	12 pc(s)
Height	360 mm	Products per pallet	216 pc(s)
Weight	577 g	Pallet gross height	18.3 cm
		Pallet gross weight	218.2 kg
		Pallet type	1200 x 1000 mm



5711045041471

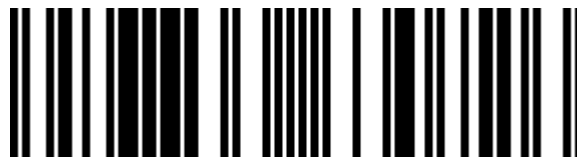

4977766630726



5715063640715

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.