




Lenovo 4Y37A78602 interface cards/adapter Internal SAS, SATA

Brand : Lenovo
Product code: 4Y37A78602
Product name : 4Y37A78602

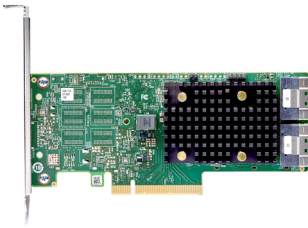

ThinkSystem 440-16i SAS/SATA PCIe Gen4 12Gb HBA

Lenovo 4Y37A78602 interface cards/adapter Internal SAS, SATA:


The ThinkSystem 440-8i and 440-16i SAS/SATA PCIe Gen4 12Gb HBAs are high performance PCIe 4.0 host bus adapters for internal storage connectivity in ThinkSystem servers. The adapters integrate the latest enhancements SAS technology and offer 8 or 16 lanes of 12 Gbps SAS.

This product guide provides essential presales information to understand the ThinkSystem HBAs and their key features, specifications, and compatibility. This guide is intended for technical specialists, sales specialists, sales engineers, IT architects, and other IT professionals who want to learn more about the HBAs and consider their use in IT solutions.

Lenovo 4Y37A78602. Host interface: PCIe, Output interface: SAS, SATA, Host interface gender: Male.

Purpose: Server, Cooling type: Passive, Certification: USA (FCC 47 CFR part 15 Subpart B, class B) Canada (ICES -003, Class B) Taiwan (CNS.... Data transfer rate (max): 12 Gbit/s

Ports & interfaces		Design	
Host interface *	PCIe	Certification	USA (FCC 47 CFR part 15 Subpart B, class B) Canada (ICES -003, Class B) Taiwan (CNS 13438) Japan (VCCI V-3) Australia/New Zealand (AS/NZS CISPR 22) Korea (RRA no 2013-24 & 25) Europe (EN55022/EN55024) Safety: EN/ IEC/ UL 60950 RoHS WEEE
Host interface gender	Male		
Output interface *	SAS, SATA		
Expansion card form factor	Low-profile		
Expansion card standard	PCIe 4.0		
Design			
Internal *	✓	Features	
Purpose	Server	Data transfer rate (max)	12 Gbit/s
Cooling type	Passive	Operational conditions	
		Operating temperature (T-T)	10 - 55 °C
		Storage temperature (T-T)	-40 - 105 °C
		Operating relative humidity (H-H)	20 - 80%
		Storage relative humidity (H-H)	5 - 95%

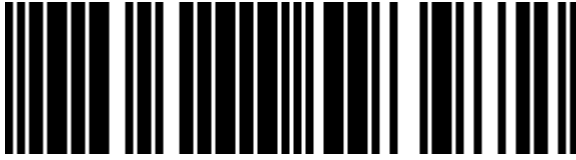

0889488593972



889488593972

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.