

## Viewsonic X2000L-4K data projector Short throw projector 2000 ANSI lumens UHD 4K (3840x2160) 3D White



**Brand :** Viewsonic

**Product code:** X2000L-4K


**Product name :** X2000L-4K

4K HDR Ultra Short Throw Smart Laser Projector

Viewsonic X2000L-4K. Projector brightness: 2000 ANSI lumens, Projector native resolution: UHD 4K (3840x2160), Contrast ratio (typical): 3000000:1. Light source type: Laser, Service life of light source: 20000 h, Lamp power: 74 W. Zoom type: Fixed, Offset: 140%. Supported graphics resolutions: 640 x 480 (VGA), 3840 x 2160, Supported video modes: 480i, 480p, 576i, 576p, 720p, 1080i, 1080p, 2160p. Serial interface type: RJ-45, HDMI connector type: Full-size

| Projector                          |                                                   | Features                           |                                                                                                                                                                                                                                    |
|------------------------------------|---------------------------------------------------|------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Smart projector *                  | ✓                                                 | On Screen Display (OSD) languages  | Arabic, Simplified Chinese, Traditional Chinese, Czech, German, Dutch, English, Spanish, Finnish, French, Greek, Hungarian, Indonesian, Italian, Japanese, Korean, Polish, Portuguese, Russian, Swedish, Thai, Turkish, Vietnamese |
| Screen size compatibility *        | 2540 - 2540 mm (100 - 100")                       |                                    |                                                                                                                                                                                                                                    |
| Projection distance                | 0.082 - 0.52 m                                    |                                    |                                                                                                                                                                                                                                    |
| Projector brightness *             | 2000 ANSI lumens                                  |                                    |                                                                                                                                                                                                                                    |
| Projector native resolution *      | UHD 4K (3840x2160)                                |                                    |                                                                                                                                                                                                                                    |
| Contrast ratio (typical) *         | 3000000:1                                         |                                    |                                                                                                                                                                                                                                    |
| Native aspect ratio *              | 16:9                                              |                                    |                                                                                                                                                                                                                                    |
| Number of colours                  | 1.07 billion colours                              |                                    |                                                                                                                                                                                                                                    |
| Vertical scan range                | 23 - 120 Hz                                       |                                    |                                                                                                                                                                                                                                    |
| Light source                       |                                                   | Number of OSD languages            | 24                                                                                                                                                                                                                                 |
| Light source type *                | Laser                                             | Screen mirroring                   | ✓                                                                                                                                                                                                                                  |
| Service life of light source *     | 20000 h                                           | Noise level *                      | 32 dB                                                                                                                                                                                                                              |
| Lamp power                         | 74 W                                              | Real cinema                        | ✓                                                                                                                                                                                                                                  |
| Lamps quantity                     | 1 lamp(s)                                         | High Dynamic Range (HDR) supported | ✓                                                                                                                                                                                                                                  |
| Lens system                        |                                                   | Eye protection                     | ✓                                                                                                                                                                                                                                  |
| Zoom type                          | Fixed                                             | Multimedia                         |                                                                                                                                                                                                                                    |
| Throw ratio                        | 0.22                                              | Built-in speaker(s) *              | ✓                                                                                                                                                                                                                                  |
| Offset                             | 140%                                              | RMS rated power                    | 50 W                                                                                                                                                                                                                               |
| Video                              |                                                   | Number of built-in speakers        | 2                                                                                                                                                                                                                                  |
| Full HD *                          | ✓                                                 | Design                             |                                                                                                                                                                                                                                    |
| 3D *                               | ✓                                                 | Market positioning *               | Home cinema                                                                                                                                                                                                                        |
| Supported graphics resolutions     | 640 x 480 (VGA), 3840 x 2160                      | Product type *                     | Short throw projector                                                                                                                                                                                                              |
| Supported video modes              | 480i, 480p, 576i, 576p, 720p, 1080i, 1080p, 2160p | Product colour *                   | White                                                                                                                                                                                                                              |
| Ports & interfaces                 |                                                   | Display                            |                                                                                                                                                                                                                                    |
| HDMI connector type                | Full-size                                         | Built-in display *                 | ✗                                                                                                                                                                                                                                  |
| HDMI version                       | 2.0                                               | Power                              |                                                                                                                                                                                                                                    |
| USB 2.0 ports quantity             | 2                                                 | Power source *                     | AC                                                                                                                                                                                                                                 |
| Headphone outputs                  | 1                                                 | Power consumption (typical) *      | 250 W                                                                                                                                                                                                                              |
| Serial interface type *            | RJ-45                                             | Power consumption (standby) *      | 0.5 W                                                                                                                                                                                                                              |
| HDMI ports quantity *              | 2                                                 | AC input voltage                   | 100 - 240 V                                                                                                                                                                                                                        |
| Component video (YPbPr/YCbCr) in * | 1                                                 | AC input frequency                 | 50 - 60 Hz                                                                                                                                                                                                                         |
| DVI port *                         | ✗                                                 | Operational conditions             |                                                                                                                                                                                                                                    |
| AC (power) in                      | ✓                                                 | Operating temperature (T-T)        | 0 - 40 °C                                                                                                                                                                                                                          |
| Audio Return Channel (ARC)         | ✓                                                 | Weight & dimensions                |                                                                                                                                                                                                                                    |
| Network                            |                                                   | Width                              | 451 mm                                                                                                                                                                                                                             |
| Smart TV *                         | ✗                                                 | Depth                              | 332 mm                                                                                                                                                                                                                             |
|                                    |                                                   | Height                             | 100 mm                                                                                                                                                                                                                             |
|                                    |                                                   | Weight *                           | 6.8 kg                                                                                                                                                                                                                             |
|                                    |                                                   | Package width                      | 577 mm                                                                                                                                                                                                                             |

| Network                     |       | Weight & dimensions              |                                                                                    |
|-----------------------------|-------|----------------------------------|------------------------------------------------------------------------------------|
| Ethernet LAN *              | ✓     | Package depth                    | 488 mm                                                                             |
| Ethernet LAN (RJ-45) ports  | 1     | Package height                   | 187 mm                                                                             |
| Wi-Fi *                     | ✓     | Package weight                   | 10 kg                                                                              |
| Bluetooth                   | ✓     | Packaging content                |                                                                                    |
| Storage                     |       | Remote control included *        | ✓                                                                                  |
| Card reader integrated *    | ✗     | Remote control type              | IR                                                                                 |
| Internal storage capacity   | 32 GB | Cables included                  | AC                                                                                 |
| Features                    |       | Packaging content                | Power Cord: 1 Remote Control: 1 (w/ backlit) QSG: Yes Warranty Card: Yes (CN Only) |
| Interactive *               | ✗     | Logistics data                   |                                                                                    |
| Noise level (economic mode) | 30 dB | Quantity per pack                | 1 pc(s)                                                                            |
| HDCP                        | ✓     | Pallet gross length              | 110 cm                                                                             |
| On Screen Display (OSD)     | ✓     | Pallet gross width               | 110 cm                                                                             |
|                             |       | Pallet gross height              | 181 cm                                                                             |
|                             |       | Products per master (outer) case | 1 pc(s)                                                                            |
|                             |       | Harmonized System (HS) code      | 8528620000                                                                         |

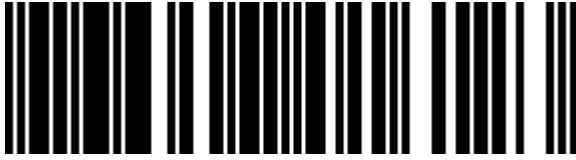

0766907016123



766907016123



0766907018165



766907018165

### Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.