



APC Easy UPS 3S 20 kVA 400V 3:1 UPS, 2 internal 7Ah modular battery strings, expandable to 3

Brand : APC

Product code: E3SUPS20K3IB1

Product name : Easy UPS 3S 20 kVA 400V 3:1 UPS, 2 internal 7Ah modular battery strings, expandable to 3

Easy UPS 3S 20 kVA 400V 3:1 UPS, 2 internal 7Ah modular battery strings, expandable to 3


APC Easy UPS 3S 20 kVA 400V 3:1 UPS, 2 internal 7Ah modular battery strings, expandable to 3:

Easy-to-install, easy-to-operate, easy-to-maintain, and easy-to-service 20 kVA 3:1 UPS. With advanced product features, competitive specifications, and robust electrical design, the Easy UPS 3S UPS makes business continuity easy for small and medium data centers and electrical rooms. Includes dust filter and conformance-coated boards for harsh environments, and 2 internal 7 Ah modular battery strings, expandable to 3 strings for extended runtime.



Features		Design	
UPS topology *	Double-conversion (Online)	Product colour *	White
Output power capacity *	20 kVA	Display type	LCD
Output power *	20000 W	LED indicators	✓
Input operation voltage (min) *	304 V	International Protection (IP) code	IP20
Input operation voltage (max) *	477 V	Operational conditions	
Input frequency *	45/65 Hz	Operating temperature (T-T)	0 - 40 °C
Output operation voltage (min)	220 V	Storage temperature (T-T)	-15 - 40 °C
Output operation voltage (max)	240 V	Operating relative humidity (H-H)	0 - 95%
Maximum current	37 A	Storage relative humidity (H-H)	0 - 95%
Number of input phases	3	Operating altitude	0 - 1000 m
Input power factor	0.99	Non-operating altitude	0 - 15240 m
Output power factor	1	Certificates	
Crest factor	3:1	Compliance certificates	CE, RoHS
ECO mode	✓	Certification	EAC, IEC 62040-1-1, IEC 62040-2, IEC 62040-3, IEC 62040-4, ISTA 2B, RCM
Emergency Power Off (EPO)	✓	Sustainability	
Output voltage Total Harmonic Distortion (THD)	3%	Sustainability compliance	✓
Input current Total Harmonic Distortion (THD)	5%	Weight & dimensions	
Battery		Width	380 mm
Battery technology	Sealed Lead Acid (VRLA)	Depth	907 mm
Battery voltage	240 V	Height	1400 mm
Number of batteries supported	2	Weight	177 kg
Typical backup time at full load	15 min	Packaging data	
Design		Package width	563 mm
Form factor *	Tower	Package depth	1014 mm
		Package height	1640 mm

Packaging data	
Package weight	186 kg
Logistics data	
Harmonized System (HS) code	85078000

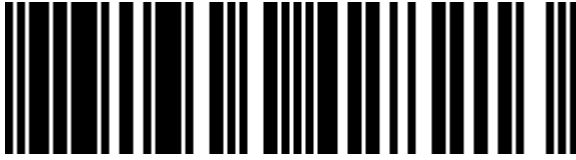

0731304428213



731304428213



8592978668006

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.