 
 
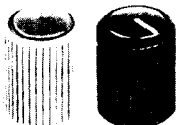
 
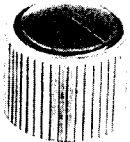
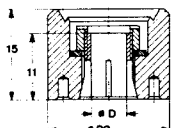
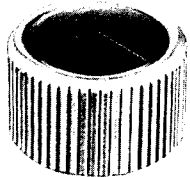
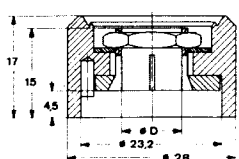
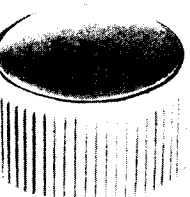
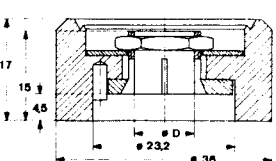
 
 
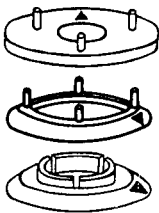
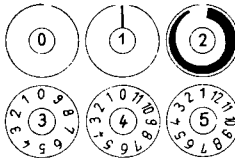
 
 
 
 
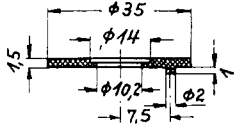
 
 
 
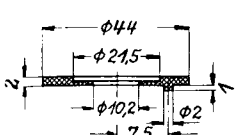
 
 


Meßgeräte-Knöpfe
mit Spannzangenbefestigung
- dekorativ farbloso eloxiert, schwarz

Instrument Knobs collet fixing
Bouton en Aluminium
- dekorativ anodized, non colored, black

					Knöpfe Knobs		Zubehör Accessoires			
					6		7	8	9	
					farblos non- colored	schwarz black	Kappe Cap	Anzeige-kappe Indicating Cap	Mutterabdeckung Nut Cover	
										
1	2	3	4	5						
Ø	Bild Photo	Maße Dimensions	D Ø	M Ncm	Art.- Nr.	Art.- Nr.	Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	
9			3 4	80 100	530.3 530.4	530.33 530.43	r sch ga c ge gü 4129.062 4129.063 4129.064 4129.065 4129.067 4129.068	183529 r sch 4129.072 4129.073	ohne Zubehör	
12			3 4 6	80 100 150	531.3 531.4 531.6	531.33 531.43 531.603	r sch ga c b ge gü 499.642 499.643 499.644 499.645 499.646 499.647 499.648	718366 r sch 499.643 531.142 531.143 531.144	ohne Zubehör	
20			6	180	532.6 183966	532.603	r sch ga c b ge gü 332.662 332.663 332.664 332.665 332.666 332.667 332.668	718714 r sch ga c b ge gü 332.662 332.663 332.664 332.665 332.666 332.667 332.668	183646 sch 332.120	
28			6 8 10	180 200 250	533.6 533.8 533.9	533.603 533.83 533.93	r sch ga b ge gü 333.662 333.663 333.664 333.666 333.667 333.668	720216 r sch ga b ge gü 333.662 333.663 333.664 333.666 333.667 333.668	533.662 533.663 533.664	
36			6 8 10	180 200 250	534.6 534.8 534.9	534.603	r sch ga 334.662 334.663 334.664	183712		

10	11	12	13	14
dto. mit Zeiger Same, with pointer	Zeiger Pointer	Zeigerscheibe Pointer dial	glasklare Scheibe Transparent dial	Grundplatte Base plate
				
Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	Ausf. Type Maße Dimensions Art.-Nr.	Ausf. Type Art.-Nr.
 sch 332.100 719811 / 183607 r 332.101 719838 ga 332.102		 sch 332.250	 0 332.200 1 332.201 2 332.202 3 332.203 4 332.204 719951 5 332.205	 1 332.300 sch 719886
	 sch 333.100 720313 / 183659 r 333.101 720321 ga 333.102	 sch 333.250	 0 333.200 1 333.201 2 333.202 3 333.203 4 333.204 5 333.205	 1 333.300 sch
	 sch 334.100 183689 r 334.101 ga 334.102		 0 334.200 1 334.201	