

Viewsonic PA503S data projector Standard throw projector 3600 ANSI lumens DLP SVGA (800x600) Grey, White

Brand : Viewsonic

Product code: PA503S

Product name : PA503S


800 x 600, DLP, 3600 ANSI lum, 30-300", 190 W, 4:3, Mini USB B, RS-232, RCA, 3.5mm, HDMI 1.4, VGA, 2x RGB, 2 W RMS, 294x218x110 mm

Viewsonic PA503S. Projector brightness: 3600 ANSI lumens, Projection technology: DLP, Projector native resolution: SVGA (800x600). Light source type: Lamp, Service life of light source: 4500 h, Service life of light source (economic mode): 15000 h. Focus: Manual, Zoom type: Manual, Optical zoom: 1.1x. Analog signal format system: NTSC, PAL, PAL 60, SECAM, Supported graphics resolutions: 640 x 480 (VGA), 720 x 480, 720 x 576, 800 x 600 (SVGA), 1024 x 768 (XGA), 1280 x 1024 (SXGA),..., Supported video modes: 480i, 480p, 576i, 576p, 720p, 1080i, 1080p. Serial interface type: RS-232, HDMI connector type: Full-size



Projector		Features	
Screen size compatibility *	762 - 7620 mm (30 - 300")	Certification	FCC (ICES-003), cTUVus
Projection distance	1.1 - 13 m	Multimedia	
Projector brightness *	3600 ANSI lumens	Built-in speaker(s) *	✓
Projection technology *	DLP	RMS rated power	2 W
Projector native resolution *	SVGA (800x600)	Number of built-in speakers	1
Native aspect ratio *	4:3	Design	
Number of colours	1.073 billion colours	Market positioning *	Business
Horizontal scan range	15 - 102 kHz	Product type *	Standard throw projector
Vertical scan range	23 - 120 Hz	Product colour *	Grey, White
Keystone correction, vertical	-40 - 40°	Placement	Desktop
Matrix size	1.4 cm (0.55")	Cable lock slot	✓
Matrix type	DMD	Cable lock slot type	Kensington
Light source		Display	
Light source type *	Lamp	Built-in display *	✗
Service life of light source *	4500 h	Power	
Service life of light source (economic mode)	15000 h	Power source *	AC
Lamp power	190 W	Power consumption (typical) *	260 W
Lamps quantity	1 lamp(s)	Power consumption (standby) *	0.5 W
Lens system		AC input voltage	100 - 240 V
Focus *	Manual	AC input frequency	50 - 60 Hz
Zoom capability	✓	Operational conditions	
Zoom type	Manual	Operating temperature (T-T)	0 - 40 °C
Optical zoom	1.1x	Operating relative humidity (H-H)	10 - 90%
Throw ratio	1.96 - 2.15:1	Operating altitude	0 - 1499 m
Video		Weight & dimensions	
Analog signal format system *	NTSC, PAL, PAL 60, SECAM	Width	294 mm
3D Ready	✓	Depth	218 mm
		Height	110 mm
		Weight *	2.22 kg

Video		Weight & dimensions	
Supported graphics resolutions	640 x 480 (VGA), 720 x 480, 720 x 576, 800 x 600 (SVGA), 1024 x 768 (XGA), 1280 x 1024 (SXGA), 1280 x 720 (HD 720), 1280 x 800 (WXGA), 1360 x 768 (WXGA), 1366 x 768, 1400 x 1050 (SXGA+), 1440 x 900 (WXGA+), 1920 x 1200 (WUXGA)	Package width	365 mm
		Package depth	300 mm
		Package height	188 mm
		Package weight	3.24 kg
Supported video modes	480i, 480p, 576i, 576p, 720p, 1080i, 1080p	Packaging content	
		Remote control included *	✓
Ports & interfaces		Cables included	AC, VGA
		Quick start guide	✓
HDMI connector type		Full-size	
HDMI version		1.4	
Serial interface type *		RS-232	
PC Audio in		✓	
PC Audio out		✓	
VGA (D-Sub) ports quantity *		3	
HDMI ports quantity *		1	
Composite video in *		1	
DVI port *		✗	
AC (power) in		✓	
Network			
Ethernet LAN *		✗	
Wi-Fi *		✗	
Storage			
Card reader integrated *		✗	

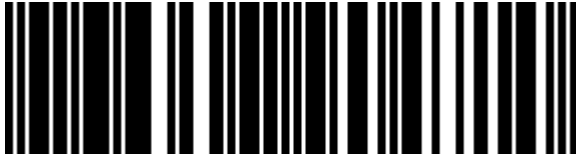

0766907904710



766907904710

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.