



QNAP QM2 interface cards/adapters Internal M.2

Brand : QNAP

Product code: QM2-2P-244A

Product name : QM2

- PCIe 2.0
 - Ready-to-use
 - SSD cache & volume
 - Efficient cooling module
 - Tool-less design
 - LED indicators & thermal sensors
- PCIe, 2 x M.2, NVMe, PCIe Gen2 x4

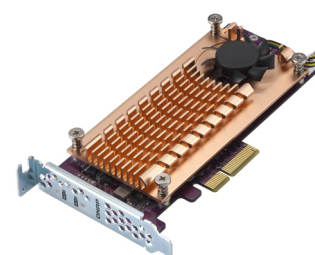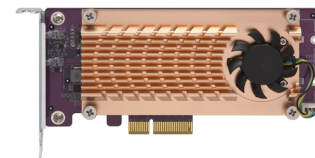

[QNAP QM2 interface cards/adapters Internal M.2:](#)

Fast, efficient, and easy-to-use

The efficient architecture of the QM2-2P-244A allows you to easily install NVMe SSDs and maximize their performance with a quiet cooling module.

Keep SSD cool

A quiet cooling module (heatsink and smart fan) keeps your SSDs running with dependable high performance.

SSD cache acceleration

Add an SSD cache or enable Qtier (QNAP's auto-tiering technology) to your NAS to improve overall system performance and maximize storage utilization.

Super-fast NVMe SSD storage volume

Photographers and videographers can tackle high-resolution RAW multimedia editing directly on NVMe SSD volumes. RAID configurations can help prevent data loss from drive failure.

Ports & interfaces		Packaging data	
Host interface *	PCIe	Mounting brackets included	✓
Output interface *	M.2	Logistics data	
Expansion card standard	PCIe 2.0	Harmonized System (HS) code	84733020
NVMe	✓	Other features	
Design		QNAP TS-431XU, TS-432XU-RP, TS-453B, TS-453BT3, TS-453BU, TS-453BU-Rp, TS-470, TS-470 Pro, TVS-470, TVS-471, TVS-471U, TVS-471U-RP, TVS-473, TVS-473eTS-653B, TS-670, TS-670 Pro, TS-677, TVS-670, TVS-671, TVS-673, TVS-673e, TVS-682, TVS-682T, TS-831XU, TS-832XU, TS-853BU, TS-853BU-RP, TS-1231XU, TS-1232XU, TS-1232XU-RP, TS-1253BU	
Internal *	✓		
Product colour	Copper		
Weight & dimensions		Compatibility	
Width	68.9 mm		
Depth	147.2 mm		
Height	20.6 mm		



4713213512913



0885022014842



885022014842

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.