



Viewsonic NMP760 PC/workstation Intel® Celeron® 5205U 8 GB DDR4-SDRAM 64 GB eMMC ChromeOS Mini PC Black

Brand : Viewsonic

Product code: NMP760


Product name : NMP760



- Disponibile per tutti gli utenti di Google Workspace for Education
- Accesso istantaneo al Google Play Store con oltre 2,95 milioni di applicazioni
- Si integra perfettamente con ViewBoard, monitor ViewSonic e proiettore ViewSonic per una completa soluzione educativa
Intel Celeron 5205U (2M Cache, 1.90 GHz), 8 GB DDR4, 64 GB eMMC, Gigabit Ethernet, WLAN, Bluetooth, ChromeOS
Viewsonic NMP760. Processor frequency: 1.9 GHz, Processor family: Intel® Celeron®, Processor model: 5205U. Internal memory: 8 GB, Internal memory type: DDR4-SDRAM. Total storage capacity: 64 GB, Storage media: eMMC, Card reader integrated. On-board graphics card model: Intel® UHD Graphics. Operating system installed: ChromeOS. Power supply: 65 W. Chassis type: Mini PC. Product type: Mini PC. Weight: 620 g. Product colour: Black

Processor		Design	
Processor manufacturer *	Intel	Chassis type *	Mini PC
Processor family *	Intel® Celeron®	Placement supported	Horizontal/Vertical
Processor model *	5205U	VESA mounting	✓
Processor cores	2	Cable lock slot	✓
Processor threads	2	Cable lock slot type	Kensington
Processor frequency *	1.9 GHz	Product colour *	Black
Processor cache	2 MB	Software	
Configurable TDP-down	12.5 W	Operating system installed *	ChromeOS
Configurable TDP-down frequency	0.8 GHz	Processor special features	
Number of processors installed	1	Intel 64	✓
Memory		Enhanced Intel SpeedStep Technology	✓
Internal memory *	8 GB	Embedded options available	✗
Internal memory type	DDR4-SDRAM	Intel Clear Video Technology	✓
Storage		Intel VT-x with Extended Page Tables (EPT)	✓
Total storage capacity *	64 GB	Intel TSX-NI	✗
Storage media *	eMMC	Idle States	✓
Optical drive type *	✗	Intel Trusted Execution Technology	✗
Card reader integrated	✓	Execute Disable Bit	✓
Compatible memory cards	MicroSD (TransFlash)	Intel Flex Memory Access	✓
Graphics		Intel Software Guard Extensions (Intel SGX)	✓
Discrete graphics card *	✗	CPU configuration (max)	1
On-board graphics card *	✓	Intel Virtualization Technology for Directed I/O (VT-d)	✓
Discrete graphics card model *	Not available	Intel Virtualization Technology (VT-x)	✓
On-board GPU manufacturer	Intel		
On-board graphics card family	Intel® UHD Graphics		
On-board graphics card model *	Intel® UHD Graphics		
Graphics card Open GL support	✓		

Performance		Display	
Trusted Platform Module (TPM)	✓	Display included *	✗
Product type *	Mini PC	Operational conditions	
Network		Operating temperature (T-T)	0 - 45 °C
Ethernet LAN *	✓	Operating relative humidity (H-H)	20 - 80%
Ethernet LAN data rates	10,100,1000 Mbit/s	Weight & dimensions	
Cabling technology	10/100/1000Base-T(X)	Width *	148.5 mm
Wi-Fi *	✓	Depth *	148 mm
Top Wi-Fi standard	Wi-Fi 6 (802.11ax)	Height *	41.7 mm
Wi-Fi standards	Wi-Fi 6 (802.11ax)	Weight *	620 g
Bluetooth	✓	Packaging data	
Bluetooth version	5.0	Package width	232 mm
Ports & interfaces		Package depth	108 mm
USB 2.0 ports quantity *	1	Package height	187 mm
USB 3.2 Gen 1 (3.1 Gen 1) Type-A ports quantity *	3	Package weight	1.27 kg
USB 3.2 Gen 1 (3.1 Gen 1) Type-C ports quantity *	1	Certificates	
HDMI ports quantity *	2	Compliance certificates	CE
Ethernet LAN (RJ-45) ports	1	Certification	FCC, FCC ID, IC ID, CB, BSMI, NCC, PSB, iDA, RCM, SDPPI, EAC, CCC
Line-in	✓	Logistics data	
Power		Pallet gross width	120 cm
Power supply *	65 W	Pallet gross length	100 cm
Power supply input voltage	100 - 240 V	Pallet gross height	115 cm
Power supply input frequency	50 - 60 Hz	Harmonized System (HS) code	8471410000
		Products per master (outer) case	5 pc(s)

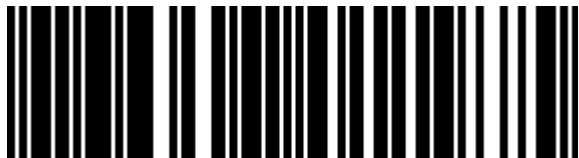

0766907011975



766907011975

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.