




**APC E3SUPS30K3IB2 uninterruptible power supply (UPS) Double-conversion (Online) 30 kVA 30000 W**

**Brand :** APC


**Product code:** E3SUPS30K3IB2

**Product name :** E3SUPS30K3IB2

Easy UPS 3S, 30 kVA, 400 V, 3:1, 50/60 Hz  
APC E3SUPS30K3IB2. UPS topology: Double-conversion (Online), Output power capacity: 30 kVA, Output power: 30000 W. Battery technology: Sealed Lead Acid (VRLA), Battery voltage: 240 V. Form factor: Rackmount, Product colour: White, International Protection (IP) code: IP20. Compliance certificates: RoHS, Certification: CE, EAC, IEC 62040-1-1, IEC 62040-2, IEC 62040-3, IEC 62040-4, ISTA 2B, RCM, WEEE. Width: 500 mm, Depth: 996 mm, Height: 1400 mm

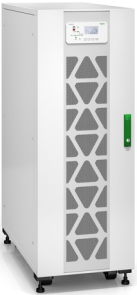

| Features                                       |                            | Design                             |                                                                                   |
|------------------------------------------------|----------------------------|------------------------------------|-----------------------------------------------------------------------------------|
| UPS topology *                                 | Double-conversion (Online) | International Protection (IP) code | IP20                                                                              |
| Output power capacity *                        | 30 kVA                     | Operational conditions             |                                                                                   |
| Output power *                                 | 30000 W                    | Operating temperature (T-T)        | 0 - 40 °C                                                                         |
| Input operation voltage (min) *                | 400 V                      | Storage temperature (T-T)          | -15 - 40 °C                                                                       |
| Input operation voltage (max) *                | 477 V                      | Operating relative humidity (H-H)  | 0 - 95%                                                                           |
| Input frequency *                              | 45/65 Hz                   | Storage relative humidity (H-H)    | 0 - 95%                                                                           |
| Output operation voltage (min)                 | 230 V                      | Certificates                       |                                                                                   |
| Output operation voltage (max)                 | 240 V                      | Compliance certificates            | RoHS                                                                              |
| Output frequency                               | 50/60 Hz                   | Certification                      | CE, EAC, IEC 62040-1-1, IEC 62040-2, IEC 62040-3, IEC 62040-4, ISTA 2B, RCM, WEEE |
| Power factor                                   | 0.99                       | Weight & dimensions                |                                                                                   |
| Crest factor                                   | 3:1                        | Width                              | 500 mm                                                                            |
| Output voltage Total Harmonic Distortion (THD) | 5.5%                       | Depth                              | 996 mm                                                                            |
| Input current Total Harmonic Distortion (THD)  | 5%                         | Height                             | 1400 mm                                                                           |
| Battery                                        |                            | Weight                             | 293 kg                                                                            |
| Battery technology                             | Sealed Lead Acid (VRLA)    | Packaging data                     |                                                                                   |
| Battery voltage                                | 240 V                      | Package width                      | 683 mm                                                                            |
| Design                                         |                            | Package depth                      | 1114 mm                                                                           |
| Form factor *                                  | Rackmount                  | Package height                     | 1640 mm                                                                           |
| Product colour *                               | White                      | Package weight                     | 297 kg                                                                            |
|                                                |                            | Logistics data                     |                                                                                   |
|                                                |                            | Harmonized System (HS) code        | 85078000                                                                          |

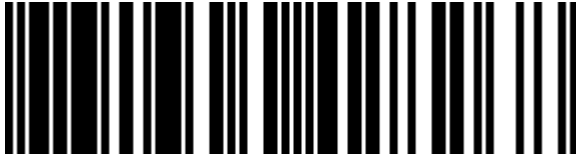

0731304428268



731304428268



3606489698041

### Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.