




Lenovo 4Y37A78834 RAID controller PCI Express x8 12 Gbit/s

Brand : Lenovo
Product code: 4Y37A78834
Product name : 4Y37A78834

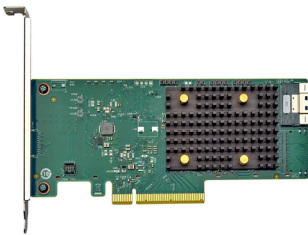

ThinkSystem RAID 540-8i PCIe Gen4 12Gb Adapter

Lenovo 4Y37A78834 RAID controller PCI Express x8 12 Gbit/s:

The ThinkSystem RAID 540 PCIe Gen4 12Gb Adapters are an entry-level 12 Gb SAS/SATA family of internal RAID adapters that offer a cost-effective RAID solution for small to medium business customers. These cacheless adapters support RAID levels 0, 1 and 10, and include an extensive list of RAS and management features.

This product guide provides essential presales information to understand the RAID 540 adapters and their key features, specifications, and compatibility. This guide is intended for technical specialists, sales specialists, sales engineers, IT architects, and other IT professionals who want to learn more about the adapters and consider their use in IT solutions.
Lenovo 4Y37A78834. Supported storage drive interfaces: PCI Express 4.0, Host interface: PCI Express x8. RAID levels: 0, 1, 10, Data transfer rate: 12 Gbit/s, Chipset: SAS3808

Ports & interfaces		Performance	
Supported storage drive interfaces * PCI Express 4.0		Certification	USA (FCC 47 CFR part 15 Subpart B, class B) Canada (ICES -003, Class B) Taiwan (CNS 13438) Japan (VCCI V-3) Australia/New Zealand (AS/NZS CISPR 22) Korea (RRA no 2013-24 & 25) Europe (EN55022/EN55024) Safety: EN/IEC/ UL 60950; RoHS; WEEE
Host interface * PCI Express x8			
Performance			
RAID levels *	0, 1, 10	Operational conditions	Operating temperature (T-T) 10 - 55 °C Storage temperature (T-T) -40 - 70 °C Operating relative humidity (H-H) 20 - 90% Storage relative humidity (H-H) 5 - 95%
Data transfer rate	12 Gbit/s		
SSD support	✓		
Chipset	SAS3808		
JBOD function	✓		
S.M.A.R.T. support	✓		
Number of devices supported	8		



0889488603008



889488603008

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.