

StarTech.com 70x15mm Replacement Ball Bearing Computer Case Fan w/ TX3 Connector

Brand : StarTech.com

Product code: FAN7X15TX3

Product name : 70x15mm Replacement Ball Bearing Computer Case Fan w/ TX3 Connector

StarTech.com 70x15mm Replacement Ball Bearing Computer Case Fan w/ TX3 Connector - 3 pin case Fan - TX3 Fan - 70mm Fan

StarTech.com 70x15mm Replacement Ball Bearing Computer Case Fan w/ TX3 Connector:

Add additional chassis cooling with a 70mm ball bearing fan

This versatile 70mm fan is an ideal replacement fan for keeping your computer running cool. The fan can be powered through a TX3 connection, and features a dual ball bearing design that ensures reliable cooling and longer fan lifespan.

The fan can be used to replace the fan component of some CPU coolers or mounted to the side panel of a computer case and features a tachometer pin on the TX3 motherboard connector that provides the host system with fan operating status information.

The StarTech.com Advantage

- A dual ball bearing design ensures reliability and longer life
- Backed by a StarTech.com 2-year warranty and free lifetime technical support




Performance		Weight & dimensions	
Suitable location *	Computer case	Width	15 mm
Type *	Fan	Depth	70 mm
Fan diameter	7 cm	Height	70 mm
Rotational speed (max)	3500 RPM	Weight	38 g
Noise level (high speed)	34 dB	Package width	96 mm
Maximum airflow	29.58 cfm	Package depth	143 mm
Mean time between failures (MTBF)	50000 h	Package height	32 mm
Operating temperature (T-T)	-10 - 70 °C	Package weight	75 g
Design		Technical details	
Product colour *	Black	Compliance certificates	RoHS
Material	Plastic	Other features	
Number of fans	1 fan(s)	Storage temperature (T-T)	-40 - 75 °C
Certification	RoHS	Operating relative humidity (H-H)	0 - 65%
Power		Dimensions (WxDxH)	10 x 60 x 60 mm
Power consumption (typical)	3.12 W	Connector(s)	1 - TX3 Female
Voltage	12 V	Rotational speed	3500 RPM
Rated current	0.18 A	Logistics data	
		Harmonized System (HS) code	84733080



0065030820387



065030820387

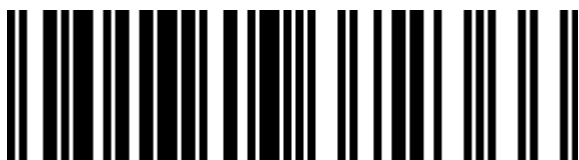

5051749372366



5054533067226

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.