



APC Base Enclosure Config (Ventilated 24U Easy Rack, SRVPM3K, PDP, Energy Meter, Local Management, Lighting)

Brand : APC

Product code: EMDC24U3KP2V

Product name : Base Enclosure Config (Ventilated 24U Easy Rack, SRVPM3K, PDP, Energy Meter, Local Management, Lighting)


- Built-in monitoring device with remote monitoring via Web access
 - Built-in Power Distribution Panel
 - Built-in LED lighting, door contact sensors front and rear to enable lights on automatically when door opens
 - Centralized management via Single IP management
- Base Enclosure Config (Ventilated 24U Easy Rack, SRVPM3K, PDP, Energy Meter, Local Management, Lighting)

APC Base Enclosure Config (Ventilated 24U Easy Rack, SRVPM3K, PDP, Energy Meter, Local Management, Lighting):

This product EMDC24U3KP2V is a configured 24U solution with pre-integrated power distribution panel, monitoring device, sensors, LED lighting and UPS Power Module. Fully enabled for EcoStruxure remote management connectivity. Made for indoor IT environments. Compact design to easily roll with recessed casters and levelling feet. Quickly deploys IT gear and connectivity to enable digitalization. APC Base Enclosure Config (Ventilated 24U Easy Rack, SRVPM3K, PDP, Energy Meter, Local Management, Lighting). Type: Freestanding rack, Rack capacity: 24U, Maximum weight capacity: 1200 kg. Weight: 110 kg. Product colour: Black

Features		Weight & dimensions	
Rack capacity *	24U	Height	1228 mm
Type *	Freestanding rack	Weight	110 kg
Maximum weight capacity *	1200 kg	Packaging data	
Maximum weight capacity (rolling)	600 kg	Package width	800 mm
Product colour	Black	Package depth	1200 mm
Weight & dimensions		Package height	1390 mm
Width	600 mm	Package weight	163 kg
Depth	1000 mm	Logistics data	
		Harmonized System (HS) code	85381000



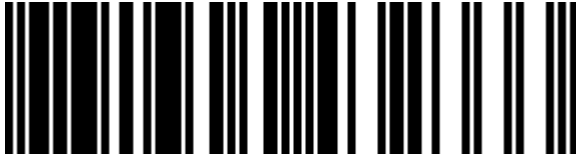

0731304432333



731304432333



4064575389430

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.