

ASUS PN64-B-S3120MD PC/workstation barebone Black i3-1220P


Brand : ASUS

Product code: PN64-B-S3120MD

Product name : PN64-B-S3120MD

Intel Core i3-1220P (12MB Cache), DDR5-SDRAM, M.2 SSD, Intel Iris Xe Graphics, LAN, WLAN, Bluetooth, No OS

ASUS PN64-B-S3120MD. Product type: Mini PC barebone. Supported memory types: GDDR5, Number of memory slots: 2. Supported storage drive types: HDD & SSD, Storage drive interface: Serial ATA III. Ethernet LAN (RJ-45) ports: 1. Wi-Fi standards: Wi-Fi 6E (802.11ax), Bluetooth version: 5.0

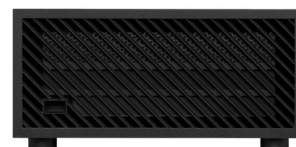

Processor		Audio	
Processor manufacturer	Intel	Built-in speaker(s) *	✗
Processor family	Intel® Core™ i3	Network	
Processor generation	12th gen Intel® Core™ i3	Top Wi-Fi standard	Wi-Fi 6E (802.11ax)
Processor model	i3-1220P	Wi-Fi standards	Wi-Fi 6E (802.11ax)
Processor cores	10	Ethernet LAN *	✓
Processor threads	12	Wi-Fi *	✓
Processor boost frequency	4.4 GHz	LAN controller	Intel WGI225V
Performance cores	2	Bluetooth	✓
Efficient cores	8	Bluetooth version	5.0
Built-in processor *	✓	Ports & interfaces	
Performance-core boost frequency	4.4 GHz	USB 3.2 Gen 2 (3.1 Gen 2) Type-A ports quantity	3
Efficient-core boost frequency	3.3 GHz	USB 3.2 Gen 2 (3.1 Gen 2) Type-C ports quantity	2
Processor cache	12 MB	HDMI ports quantity *	2
Memory		HDMI version	2.0
Memory slots type *	SO-DIMM	DisplayPorts quantity	1
Number of memory slots *	2	DisplayPort version	1.4
Supported memory clock speeds	4800 MHz	Combo headphone/mic port	✓
Supported memory types	GDDR5	Ethernet LAN (RJ-45) ports *	1
Storage		DC-in jack	✓
Supported storage drive types *	HDD & SSD	Design	
Storage drive sizes supported *	2.5,M.2	Product colour *	Black
SSD form factor	M.2	Cable lock slot	✓
Storage drive interface	Serial ATA III	Cable lock slot type	Kensington
Number of storage drives supported	2	VESA mounting	✓
Graphics		Product type *	Mini PC barebone
On-board graphics card *	✓	Certificates	
Graphics card family	Intel	Certification	BSMI/CB/CE/FCC/UL/CCC/Energy Star/C-Tick/WiFi/RF/VCCI
On-board graphics card model	Intel® UHD Graphics	Software	
Discrete graphics card model	Not available	Operating system installed	✗
Performance		Power	
Trusted Platform Module (TPM)	✓	Power supply type *	External AC adapter
Audio chip	Realtek ALC897		

Weight & dimensions

Width	120 mm
Depth	130 mm
Height	58 mm
Weight	750 g



4711387152683

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.