



Impedance	50 Ω
Frequency range	0 to 4GHz
Voltage rating	500 volts peak
Dielectric withstanding voltage	1500 volts rms
VSWR	N39012 straight connectors: 1.3 max. 0-4GHz N39012 right angle: 1.3 max. 0-4GHz
Other (MIL-C-39012 Cable Connectors)	Contact resistance: center contact 1.5 milliohm outer contact 0.2 milliohm Insertion loss: 0.2db max at 3.0GHz Insulation resistance: 5000 megohms(min)

5	Lock Washer	Brass	Nickel
4	Nut	Brass	Nickel
3	Insulator	Delrin	White
2	Contact	PH/Bronze®	Gold
1	Body	Brass	Nickel
NO	Description	Material	Finish

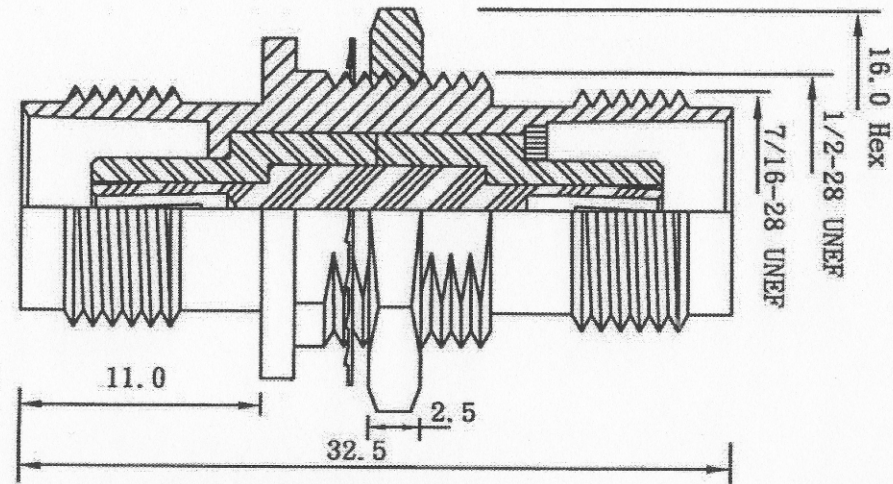

NOTE: FINISH (PLATING THICKNESS IN MICRO-INCHES)  
 1. BODY/CONTACT: BRASS PER JIS-C3604  
 2. CONNECTOR INTERFACE PER MIL-STD-348A  
 3. PART TO BE CLEAN AND FREE BURRS  
 4. NICKEL PL 70 u" THICK OVER COPPER STRIKE  
 5. GOLD PL 1-3 u" OVER NICKEL PL 70 u" THICK OVER COPPER STRIKE

Mounting Holes

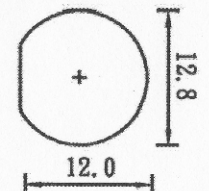

**Artikelnummer**    **Artikeltext**  
 730451                Einbauadapter, Einlochmontage, TNC-Buchse auf TNC-Buchse, 50 Ohm