
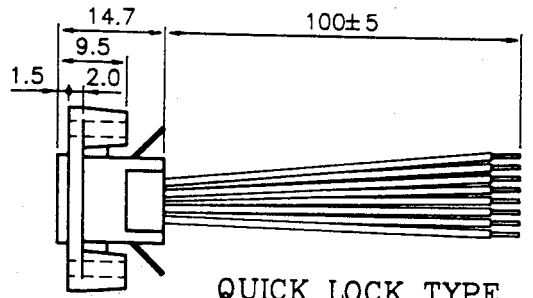


STANDARD TYPE

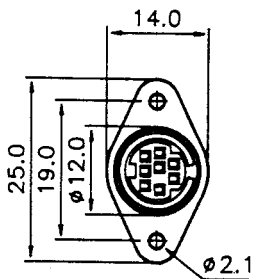

QUICK LOCK TYPE

**Specifications**

Rating: 100V AC 1A MAX or  
12V DC 2A MAX

Insulation Resistance:  
50MΩ MIN at 250V DC

Dielectric Strength:  
250V AC/1 minute

Contact Resistance:  
30mΩ MAX

Insertion Force:  
4.5kg MAX

Withdrawal Force:  
0.9kg~3kg

Wire: Awg #26

WIRE: AWG26 (#1061)

ARRANGEMENT OF CONTACTS							
NO OF CONTACTS	3	4	5	6	7	8	
WIRE COLOR	1 2 3 4 5 6 7 8	BLACK GREEN YELLOW RED -- -- -- --	BLACK GREEN YELLOW RED -- -- -- --	BROWN BLACK GREEN YELLOW RED -- -- --	BROWN WHITE BLACK GREEN YELLOW RED -- --	BROWN WHITE BLACK GREEN YELLOW ORANGE RED --	BROWN WHITE BLACK BLUE GREEN YELLOW ORANGE RED

ORDER NO. OF CABLE ASSEMBLIES:

POLE	STANDARD	QUICK LOCK
3	7303-L.	7313-L.
4	7304-L.	7314-L.
5	7305-L.	7315-L.
6	7306-L.	7316-L.
7	7307-L.	7317-L.
8	7308-L.	7318-L.

L.=Length (Standard Length=10cm)