



## Product information G 30 W 3 F grau/grey

Industrial Connecting Solutions:Rectangular Connectors:DIN VDE 0627 / IEC 61984 Connectors (G serie):Cable socket:G 30 W 3 F grau/grey

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-24347-24348-36910/en/conf/ui/state>

Name G 30 W 3 F grau/grey



Cable socket with PG 7 cable gland and solder contacts

### Delivery informations

Availability available

### Product description

Description Cable socket with PG 7 cable gland and solder contacts

Type G 30 W 3 F grau/grey

Order No. 932 186-106

Type of contact forked spring

Number of contacts 3 + PE

Cable gland PG 7

Conductor size max. 0.5 mm<sup>2</sup>

Standard DIN VDE 0627 / IEC 61984

Housing Color grey

### Technical data

Rated voltage AC/DC 250 V

Rated current 6 A

Contact resistance <= 4 mOhm

Type of termination solder

Suitable cables 4 mm to 7.5 mm

### Material

Contact surface material Sn

Contact bearer material PA

Housing material PA

### Environmental conditions

Protection class (IEC 60529) IP 65

Pollution severity 3

Temperature range -40 °C to +90 °C

### Inflammability class

Housing 94 HB

Contact bearer 94 HB

### Approvals

VDE VDE

### Packaging unit

Packaging unit 100 pieces

### Scope of delivery and accessories

Scope of delivery 1 cable socket with PG 7 cable gland, 1 central screw M 3 x 20, 1 gasket, not assembled, in polythene bag

Accessories to order separately can be plugged into G 30 E 3 M, G 30 A 3 M grau/grey



# HIRSCHMANN


A BELDEN BRAND

Industrial Connecting Solutions: Rectangular Connectors: DIN VDE 0627 / IEC 61984 Connectors (G serie): Cable socket: G 30 W 3 F grau/grey

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-24347-24348-36910/en/conf/ui/state>

Picture

Drawing

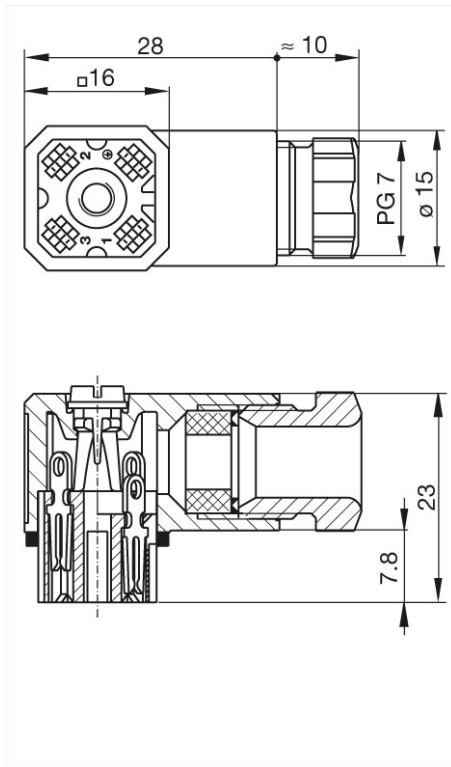

#### Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.