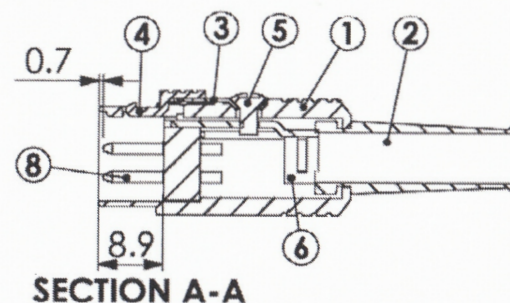


8	Terminals	Brass	Silver Ptd.	4
7	4P Housing	ABS		1
6	"T" Holder	Steel	Nickel Ptd.	1
5	Setscrew	Steel	Nickel Ptd.	1
4	Hook Button	Zn Alloy	Nickel Ptd.	1
3	Leaf Spring	Steel	Thermal Treatment	1
2	Strain Boot	PVC		1
1	Shield Cover	Zn Alloy	Nickel Ptd.	1

Specifications

rating :
100V AC 4A MAX
contact resistance :
pins-30mΩ MAX; shell-50mΩ MAX
Insulation resistance :
MIN 100 MEGΩ @500V DC
voltage withstand :
250V AC R.M.S. for 1 minute

Artikelnummer	Artikeltext
735363	DIN Stecker mit Verriegelung, 4-polig