

ASUS ZenDrive V1M (SDRW-08V1M-U) optical disc drive DVD±RW Black


Brand : ASUS

Product code: 90DD02L0-M29000

Product name : ZenDrive V1M (SDRW-08V1M-U)

- Convenient cable storage: No more losses with a built-in 24cm connecting cable.
- USB-C interface: Perfect companion for latest-generation ultraslim laptops.
- M-DISC support: Store your precious photos, videos and data for up to 1,000 years.
- Windows or macOS: Cross-platform support for broad compatibility.
- Drag and burn: Create a disc in just three steps, via intuitive interface. (Windows only)
- Disc Encryption: Hassle-free data protection through password control and hidden-folder functions. (Windows only)
- Backup software included: Nero BackItUp enables easy archival of photos, videos or data. (Windows only)

ASUS ZenDrive V1M external DVD drive and writer with built-in cable-storage design, USB-C® interface, compatible with Windows 11 and macOS, M-DISC support, comprehensive backup solutions included

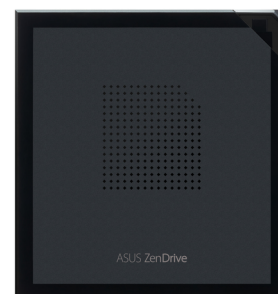

Design		Reading speed	
Internal *	✗	DVD+R read speed	8x
Product colour	Black	DVD-R read speed	8x
Disc loading type	Front	DVD-RW read speed	8x
Performance		DVD-ROM read speed	8x
Purpose *	Desktop/Laptop	DVD+RW read speed	8x
Optical drive type *	DVD±RW	System requirements	
Interface *	USB Type-C	Windows operating systems supported	Windows 10, Windows 11, Windows 8, Windows 8.1
Disc types supported	CD-R, CD-ROM, DVD+R, DVD+R DL, DVD+RW, DVD-R, DVD-R DL, DVD-ROM, DVD-RW	Mac operating systems supported	Mac OS X 10.10 Yosemite, Mac OS X 10.11 El Capitan, Mac OS X 10.12 Sierra, Mac OS X 10.13 High Sierra, Mac OS X 10.14 Mojave, Mac OS X 10.15 Catalina, Mac OS X 10.15.3 Catalina, Mac OS X 10.6 Snow Leopard, Mac OS X 10.7 Lion, Mac OS X 10.8 Mountain Lion, Mac OS X 10.9 Mavericks
Writing speed		Weight & dimensions	
CD write speed *	24x	Width	142 mm
CD-R write speed	24x	Depth	150 mm
CD-RW write speed	24x	Height	14.6 mm
DVD+R write speed *	8x	Weight	255 g
DVD-R write speed	8x	Packaging content	
DVD+RW write speed	8x	Bundled software	CyberLink Power2Go 8 CyberLink PowerBackup 2.6 Nero BackItUp E-Green
DVD-RW write speed	6x	Logistics data	
Reading speed		Harmonized System (HS) code	84717030
CD read speed *	24x		
CD-R read speed	24x		
CD-ROM read speed	24x		



4711081450634



0195553473460



195553473460

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.