
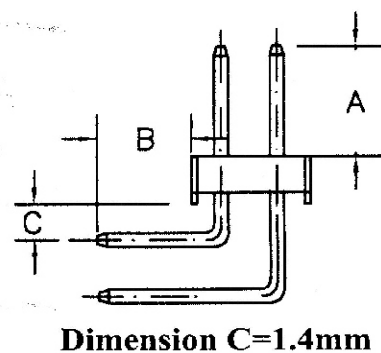


SPECIFICATIONS

Current Rating: 3 Amperes
 Insulation Resistance: 1000MΩ Min
 Dielectric Withstanding: 600V AC/DC
 Contact Resistance: 20mΩ Max.
 Operating Temperature: -40°c to +105°c

MATERIALS

Contact Material: Copper Alloy
 Contact Plating: Gold / Tin over Nickel
 Insulator: Glass Filled Polyester (UL 94V-0)
 P.B.T or Nylon-6T
 All materials must be RoHS compliant.

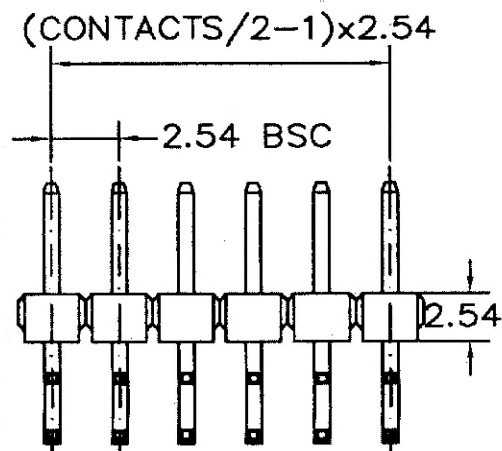

Terminal Code	Dimensions(mm)	
	A	B
RN	3.5	3.3
RP	4.8	3.3
RQ	6.1	3.3
RR	6.9	3.3
RS	9.9	3.3
RT	12.0	3.3
LN	13.8	3.3
LR	15.0	3.3
LT	17.1	3.3
MK	4.9	3.5
ML	3.0	6.0
MX	5.8	3.0
RC	6.0	3.6
RV	5.7	2.5
MY	4.0	2.8

Datenblatt passend zu folgenden Artikelnummern
10120530 / 10120532 / 10120534
10120175 / 10120176 / 10120177 / 10120178 / 10120179 / 10120180