

## SPECIFICATIONS

**Current Rating:** 3 Amperes

**Insulation Resistance:** 1000M $\Omega$  Min

**Dielectric Withstanding:** 600V AC/DC

**Contact Resistance:** 20m $\Omega$  Max.

**Operating Temperature:** -40 $^{\circ}$ c to +105 $^{\circ}$ c

## MATERIALS



**Contact Material:** Copper Alloy

**Contact Plating:** Gold / Tin over Nickel

**Insulator:** Glass Filled Polyester (UL 94V-0)

P.B.T or Nylon-6T

**All materials must be RoHS compliant.**

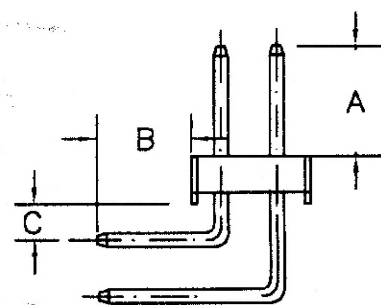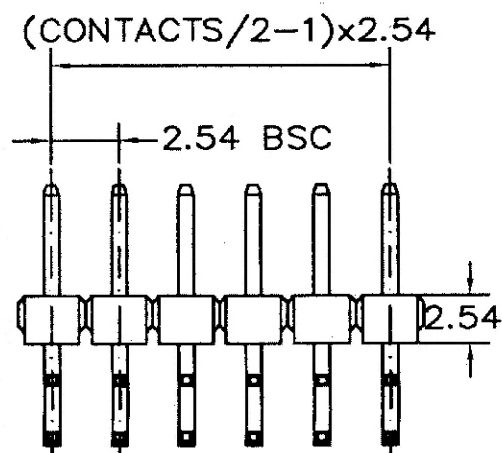

Dimension C=1.4mm

Terminal Code	Dimensions(mm)	
	A	B
RN	3.5	3.3
RP	4.8	3.3
RQ	6.1	3.3
RR	6.9	3.3
RS	9.9	3.3
RT	12.0	3.3
LN	13.8	3.3
LR	15.0	3.3
LT	17.1	3.3
MK	4.9	3.5
ML	3.0	6.0
MX	5.8	3.0
RC	6.0	3.6
RV	5.7	2.5
<del>MY</del>	4.0	2.8

Datenblatt passend zu folgenden Artikelnummern

10120530 / 10120532 / 10120534

10120175 / 10120176 / 10120177 / 10120178 / 10120179 / 10120180