

SPECIFICATIONS

Current Rating: 3 Amperes

Insulation Resistance: 1000M Ω Min

Dielectric Withstanding: 600V AC/DC

Contact Resistance: 20m Ω Max.

Operating Temperature: -40 $^{\circ}$ c to +105 $^{\circ}$ c

MATERIALS



Contact Material: Copper Alloy

Contact Plating: Gold / Tin over Nickel

Insulator: Glass Filled Polyester (UL 94V-0)

P.B.T or Nylon-6T

All materials must be RoHS compliant.

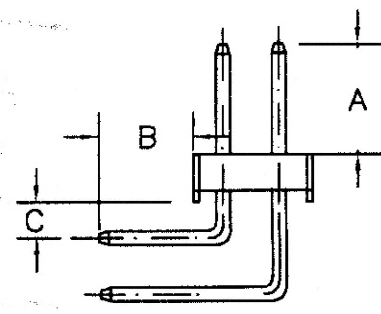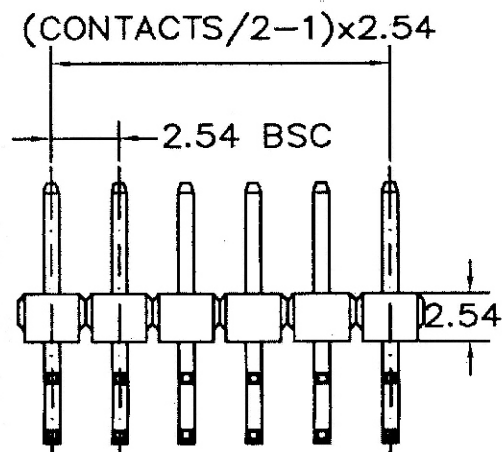

Dimension C=1.4mm

Terminal Code	Dimensions(mm)	
	A	B
RN	3.5	3.3
RP	4.8	3.3
RQ	6.1	3.3
RR	6.9	3.3
RS	9.9	3.3
RT	12.0	3.3
LN	13.8	3.3
LR	15.0	3.3
LT	17.1	3.3
MK	4.9	3.5
ML	3.0	6.0
MX	5.8	3.0
RC	6.0	3.6
RV	5.7	2.5
MY	4.0	2.8

Datenblatt passend zu folgenden Artikelnummern

10120530 / 10120532 / 10120534

10120175 / 10120176 / 10120177 / 10120178 / 10120179 / 10120180