


Filter-D-Sub-Steckverbinder, mit Ferritplatte, gewinkelt Filtered D-Sub-connectors, with ferrite plate, angled

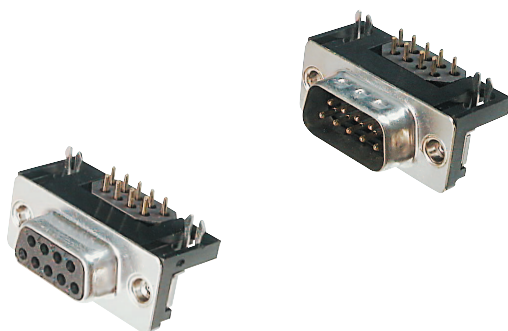

Isolierkörper
PBT, UL94V-0

Gehäuse
Stahl

Betriebstemperaturbereich
-55°C bis +105°C

Stromnennbelastung
3A




Insulators
PBT, UL94V-0

Shell
Steel

Operating temperature
-55°C to +105°C

Current rating
3A

Dimensions					
No. of contacts	A	B	C	D	E
09	30.81	24.99	16.92	16.33	11.08
15	39.14	33.32	25.50	24.66	19.39
25	53.04	47.04	38.96	38.38	33.24
37	69.32	63.50	54.42	55.84	49.86

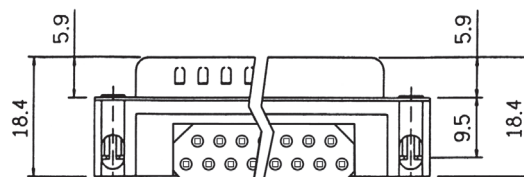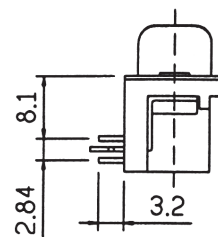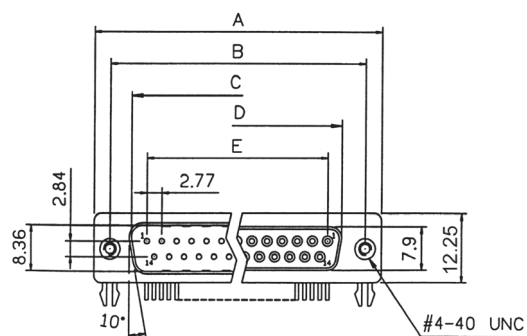

Bestellcode : **A - D - x - x - A / KG - F** Bitte „x“ durch unten geeignete Option ersetzen
Ordercode : **A - D - x - x - A / KG - F** Please replace „x“ with appropriate option listed below

1. 2.

1.

Kontaktart
F -Buchse
S -Stecker

Contact type
F -Female
S -Male

2.

Polzahl
09, 15, 25, 37

No. of contacts
09, 15, 25, 37

Standard: Anforderungsstufe III

Standard: Quality class III