

 





Data Sheet

Toggle switch 250 VAC 3 A 1x on/on, TRU Components



Drawing:

T80-T

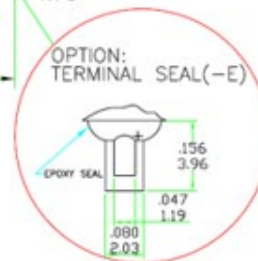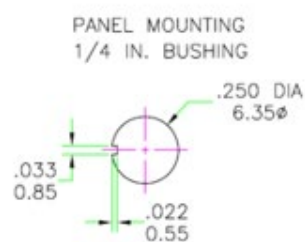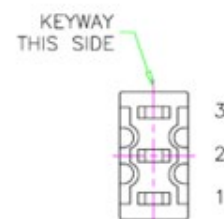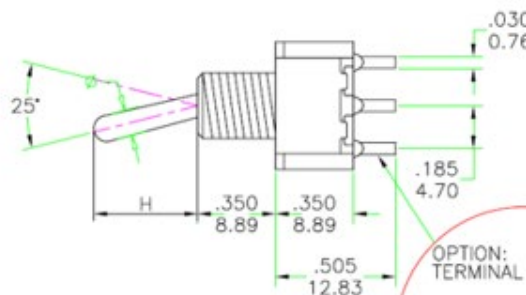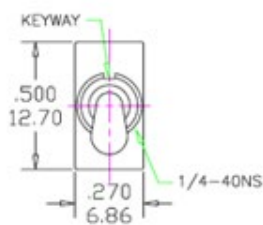

Actuator	H	Ø
S	10.41	Ø3.00
T	5.50	Ø2.70

Data Sheet

Technical data

Toggle length:	10.41 mm
Color:	RED
Switch function:	ON-ON
Switching voltage & current:	3 A 250 VAC / 5 A 125 VAC
Number of pins:	3PCS
Connection:	Solder tag
Operation temperature:	-10 °C~+80 °C
Storage temperature:	-40 °C~+80 °C
Dielectric strength:	1500 V
Insulation resistance:	DC 500 V 1000 MΩ OR MORE
Contact resistance:	DC 2-4 V 1 A 10 MΩ OR LESS
Electrical life cycle:	6000 times
Mechanical life cycle:	50000 times