 
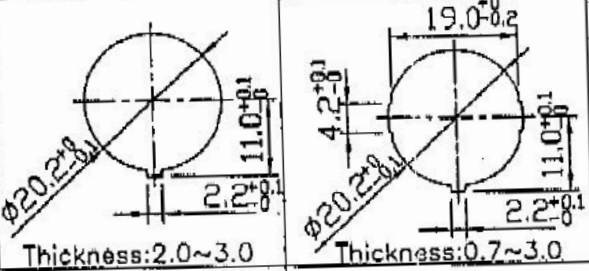
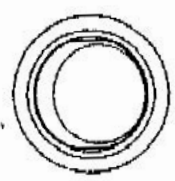
 

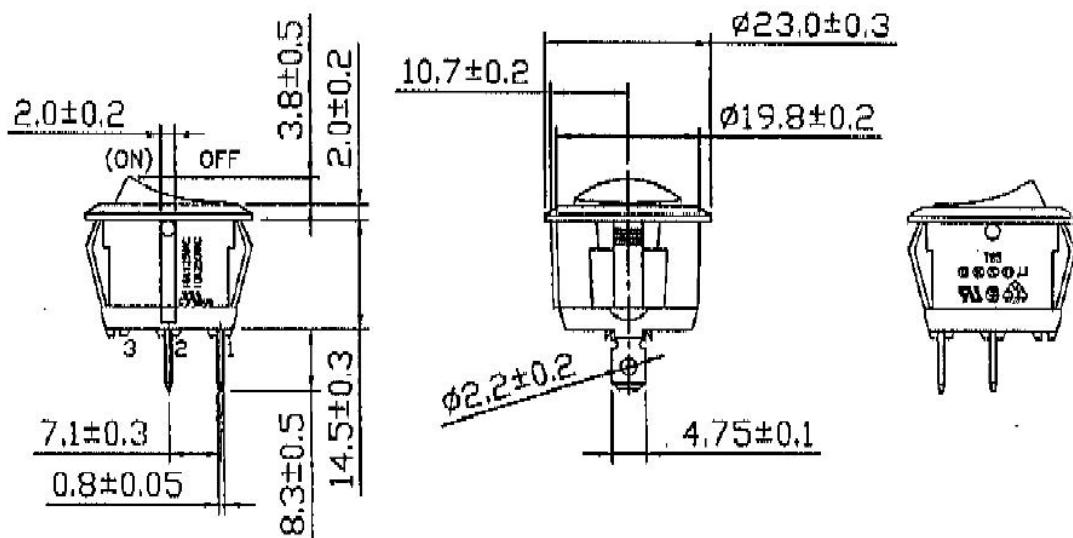


Rocker Switch, B/B no mark

Rating	6A 250VAC 	Mount Hole
	10A 125VAC	
Contact R	50m ohm Max.	
Insulation R	DC 500V 100M ohm Min.	
Dielectric Strength	AC 1500V 1 minute	
Operation Tempure	-20°~85°	
Circuit	2P SPST (ON)-OFF	
 <p>Frame:Nylon 66 (Black) Actuator:PC (Red)</p>		<p>Thickness:2.0~3.0</p> <p>Thickness:0.7~3.0</p>
		<p>Circuit Structure</p> <p>OFF </p> <p>ON </p>



*MATERIAL--Frame: Nylon 66 (Black)
Actuator: PC (Red)
Terminals: C1100R-1/2H with Silver plated
Contacts: AgSnO2InO3



Unit: mm