
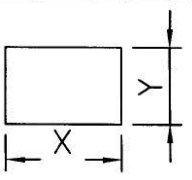
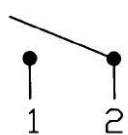


Rocker Switch

Rating	10A 24VDC	Mounting Hole	Circuit											
	50m ohm Max.													
Contact Resistance	50m ohm Max.													
Insulation Resistance	DC 500V 100M ohm Min.													
Dielectric Strength	AC 1500V 1 minute	<table border="1"> <thead> <tr> <th>Thickness</th> <th>X</th> <th>Y</th> </tr> </thead> <tbody> <tr> <td>0.75...1.25</td> <td>30.2-0.1</td> <td>11.2+0.1</td> </tr> <tr> <td>1.25...2</td> <td>30.4-0.1</td> <td>11.2+0.1</td> </tr> <tr> <td>2...3</td> <td>30.8-0.1</td> <td>11.2+0.1</td> </tr> </tbody> </table>	Thickness	X	Y	0.75...1.25	30.2-0.1	11.2+0.1	1.25...2	30.4-0.1	11.2+0.1	2...3	30.8-0.1	11.2+0.1
Thickness	X		Y											
0.75...1.25	30.2-0.1		11.2+0.1											
1.25...2	30.4-0.1	11.2+0.1												
2...3	30.8-0.1	11.2+0.1												
Operation Temperature	-20°C ~ 85°C													
Switch Function	2P SPST ON-OFF													

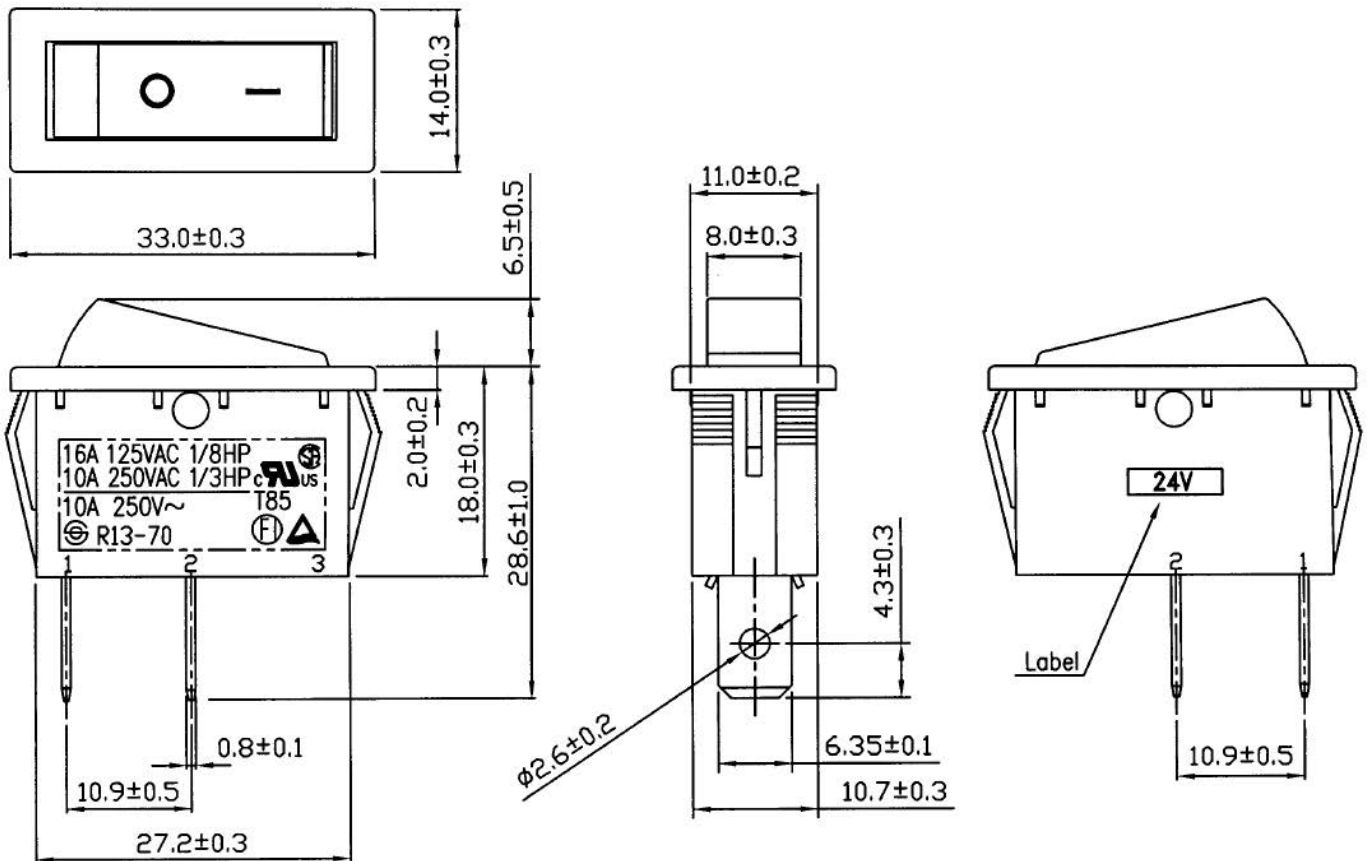

Unit: mm